


EPIC® HA 32 Standard Hoods

Double Lever Bolts

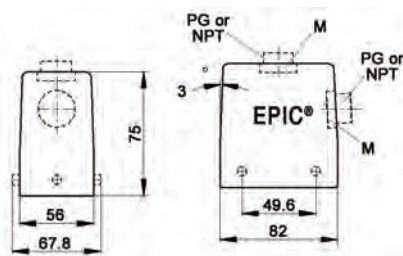

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652, DIN 50262 (metric)	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Size of Entry			Part Number			Complete the Installation: SKINTOP® Strain Relief, page 368			
PG	NPT	Metric	PG	NPT	Metric*	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
21	3/4"	25	105820	105820NP	19582000	53015050	52015750	53111030	53112030
29	1"	32	105830	105830NP	19583000	53015060	52015760	53111040	53112040
—	—	40	—	—	79520600	—	—	53111050	53112050
Side Entry									
21	3/4"	25	105760	105760NP	19576000	53015050	52015750	53111030	53112030
29	1"	32	105770	105770NP	19577000	53015060	52015760	53111040	53112040
—	—	40	—	—	19577500	—	—	53111050	53112050

* Metric hoods do not come with a neck

Approvals




Complete the Installation


HA Dust
Covers:
page 415

EPIC® HA 32 Panel Mount Bases

Double Levers

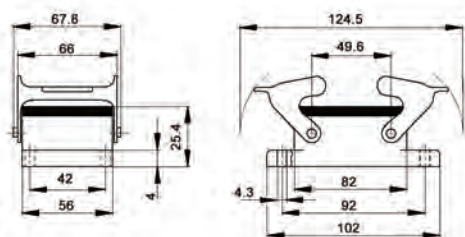

All dimensions are in mm.

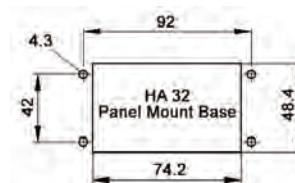

Technical Data

Specifications:	DIN 43652, DIN 50262 (metric)	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Description	Part Number
Panel Mount Base	104720C0

Complete the Installation


HA Dust
Covers:
page 415

Approvals



EPIC® HA 32 Surface Mount Bases

Double Levers

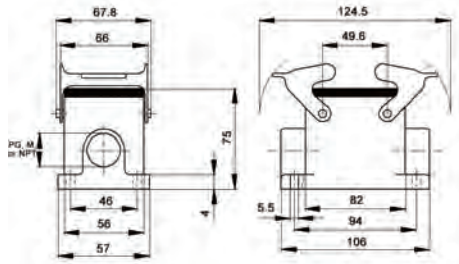

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652, DIN 50262 (metric)	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Size of Entry			Part Number			Complete the Installation: SKINTOP® Strain Relief, page 368			
PG	NPT	Metric	PG	NPT	Metric*	PG Nylon	PG Metal	Metric Nylon	Metric Metal
2 Entries									
21	3/4"	25	104820	104820NP	19482000	53015050	52015750	53111030	53112030
29	1"	32	104821	104821NP	19482100	53015060	52015760	53111040	53112040
—	—	40	—	—	79506800	—	—	53111050	53112050
1 Entry									
21	3/4"	25	104740	104740NP	19474000	53015050	52015750	53111030	53112030
29	1"	32	104741	104741NP	19474100	53015060	52015760	53111040	53112040

* Metric bases do not come with a neck

Approvals




Complete the Installation



HA Dust
Covers:
page 415

EPIC® HA 32 Cable Coupler Hoods

Double Levers

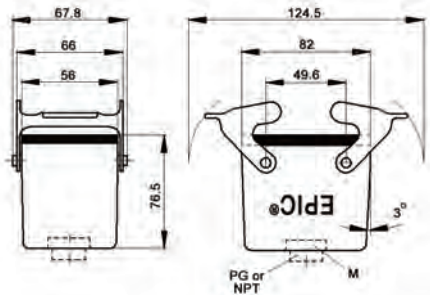

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652, DIN 50262 (metric)	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Size of Entry			Part Number			Complete the Installation: SKINTOP® Strain Relief, page 368			
PG	NPT	Metric	PG	NPT	Metric*	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Standard Profile									
21	3/4"	25	105880	105880NP	19588000	53015050	52015750	53111030	53112030
29	1"	32	105885	105885NP	19588500	53015060	52015760	53112030	53112040

* Metric hoods do not come with a neck

Approvals



Complete the Installation



HA Dust
Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.
For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.