


SKINTOP® SL/SLR

Strain Relief with PG Thread

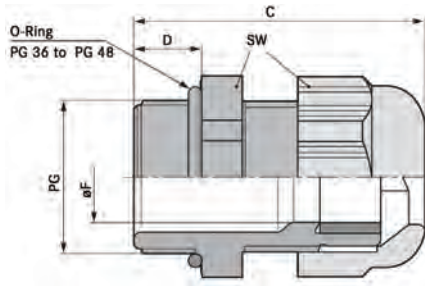

Similar Products

- SKINTOP® FLEX

Complete the Installation

SKINTOP® DIX Bushing: page 548

Plugs: page 550

SKINTOP® SL/SLR is a durable, liquid-tight, easy-to-assemble strain relief cable gland with PG thread that is universally suited for all types of machinery & equipment, including automation, motion control, process control and robotics.

Approvals



Application Advantage

- The heavy duty SKINTOP® design provides great pullout strength and very reliable strain relief
- Superior integrated locking mechanism includes an internal ratchet for vibration-proof protection
- Multi-trapezoidal thread requires just one twist to tighten
- Generous high-quality neoprene bushing provides a liquid-tight and dust-proof hermetic seal

Technical Data

Material:		RAL Color:	Black (RAL 9005), UV resistant Gray (RAL 7001)
- Body:	Polyamide		
- Bushing:	CR		
Locknuts:	Included	IP Protection:	70 PSI IP68, 5 bar (Exceeds NEMA 6/6P pressure rating)
- Seal:			
Temperature Range:			
- Static:	-40°C to +80°C		
- Dynamic:	-20°C to +80°C		

Part Number	Thread Type & Size	UL Status	øF Clamping Range		SW Wrenching Flats (inches)	C Overall Length (inches)	D Thread Length (inches)	Standard Pack Size
			(inches)	(mm)				
SKINTOP® SL: Standard								
S2107	PG 7	Recognized	0.098 - 0.256	2.5 - 6.5	0.591	1.260	0.315	100
S2109	PG 9	Recognized	0.138 - 0.315	3.5 - 8.0	0.748	1.417	0.315	100
S2111	PG 11	Recognized	0.157 - 0.394	4.0 - 10.0	0.866	1.496	0.315	100
S2113	PG 13	Listed	0.236 - 0.472	6.0 - 12.0	0.945	1.614	0.354	100
S2116	PG 16	Listed	0.354 - 0.551	9.0 - 14.0	1.063	1.732	0.394	50
S2121	PG 21	Listed	0.512 - 0.709	13.0 - 18.0	1.299	1.929	0.433	50
S2129	PG 29	Recognized	0.551 - 0.984	14.0 - 25.0	1.654	2.205	0.433	25
S2136	PG 36	Listed	0.945 - 1.260	24.0 - 32.0	2.087	2.598	0.512	10
S2142	PG 42	Recognized	1.378 - 1.496	35.0 - 38.0	2.362	2.677	0.512	5
S2148	PG 48	Listed	1.535 - 1.732	39.0 - 44.0	2.559	2.717	0.551	5
SKINTOP® SLR: Reducer Bushing								
S2207	PG 7	Recognized	0.059 - 0.197	1.5 - 5.0	0.591	1.260	0.315	100
S2209	PG 9	Recognized	0.079 - 0.236	2.0 - 6.0	0.748	1.417	0.315	100
S2211	PG 11	Recognized	0.079 - 0.276	2.0 - 7.0	0.866	1.496	0.315	100
S2213	PG 13	Listed	0.157 - 0.354	4.0 - 9.0	0.945	1.614	0.354	100
S2216	PG 16	Listed	0.236 - 0.472	6.0 - 12.0	1.063	1.732	0.394	50
S2221	PG 21	Listed	0.354 - 0.630	9.0 - 16.0	1.299	1.929	0.433	50
S2229	PG 29	Recognized	0.433 - 0.787	11.0 - 20.0	1.654	2.205	0.433	25
S2236	PG 36	Listed	0.669 - 1.024	17.0 - 26.0	2.087	2.598	0.512	10
S2242	PG 42	Recognized	0.866 - 1.220	22.0 - 31.0	2.362	2.677	0.512	5
S2248	PG 48	Listed	1.024 - 1.378	26.0 - 35.0	2.559	2.717	0.551	5

Orders of 2000 pieces or more per item will be bulk packaged unless otherwise requested.

Photographs are not to scale and are not true representations of the products in question. For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.