

Description

The Defibrillator Emergency Phone Tower, model **ETP-MT/R-AED** provides outdoor access to a life-saving Automated External Defibrillator (AED), which can be unlocked immediately at the initiation of a phone call by a remotely by a guard.

Features

- Secured, recessed chamber to house AED unobtrusively
- Optional thermostatically controlled heater for AED compartment maintains temperature above freezing
- AED door can be either unlocked immediately at the initiation of a phone call or remotely by a guard as determined by the installer
- Available Key Reset Relay option allows the Blue Light to continuously flash until physically deactivated
- ETP-MT/R tower offers contemporary architectural styling and even greater visibility than standard tower due to it's larger size and radius corners
- Attention-getting LED Blue Light is included and mounted atop the unit. The LED Blue Light is continuously lit and flashes for duration of a call when "EMERGENCY" button is pressed to draw attention to the unit
- LED Blue Light is housed in a protective polycarbonate housing (except OP4, OP5)
- Two ultra bright LED panel lights illuminate both the phone and the AED compartment at all times
- Vandal-resistant structure and coating designed to resist extreme weather conditions
- A variety of signage, graphics and color choices are available
- ADA-compliant

Specifications

Dimensions (W x D x H):	12.0 x 10.0 x 108.0 in. (305 x 254 x 2743 mm) with 2 in. radius corners
Weight:	400 lbs. (181 kg)
Construction:	0.25 in. steel
Coating:	High-gloss, multi-layer, corrosion-inhibitive system with resistance to UV-fade and graffiti protection
Colors:	Safety Blue is standard. Available in custom colors.
Signage:	3.25 in. high reflective white "EMERGENCY" lettering with wide-angle visibility is standard. Available in custom colors, lettering and graphics.
Lighting:	<p>LED Blue Light: 209 lumens peak, 78 flashes per minute, 70% of initial lumens after 50,000 hours of operation</p> <p>LED Panel Light: Ultra bright LEDs, 50,000 hour lifetime</p>
Power:	<p>LED Blue Light: 7.8 watts, 120VAC 7.8 watts, 12-24VDC/24VAC</p> <p>LED Panel Light: 1.2 watts, 12-120VAC/DC</p>
Mounting:	Mounts into concrete foundation using included hardware (shipped in advance). Mounting options available for pre-poured parking decks.
Warranty:	5-year warranty on tower (2-year warranty on electronics)



ETP-MT/R-AED – Defibrillator Emergency Phone Tower

Options

ETP-MT/R Configuration	Emergency Phone Options	Tower Options
Analog Connectivity	ETP-400 Series Phone	ETP-MT/R-AED- OP2 includes a housing for mounting your own fixed CCTV camera inside the tower at average face height. ETP-MT/R-AED- OP3 includes a Honeywell fixed day/night CCTV camera inside the tower at average face height.
IP Connectivity	VOIP-500 Series Phone	ETP-MT/R-AED- OP4 includes an arm for mounting your own CCTV dome camera above the tower. ETP-MT/R-AED- OP5 includes an arm for mounting an AD Speed-Dome Ultra camera above the tower.

ETP-MT/R-AED tower includes a LED Blue Light, two LED Panel Lights and an Anchor Bolt Kit. Emergency Phone and defibrillator are purchased separately.

Accessories


Parking Deck Mounting Kit:

Order model **ETP-PDMK-4** to mount on pre-poured parking deck.

Heater Option:

Add "**HTR**" to the model number for built-in AED enclosure heater.

Dimensional Diagram

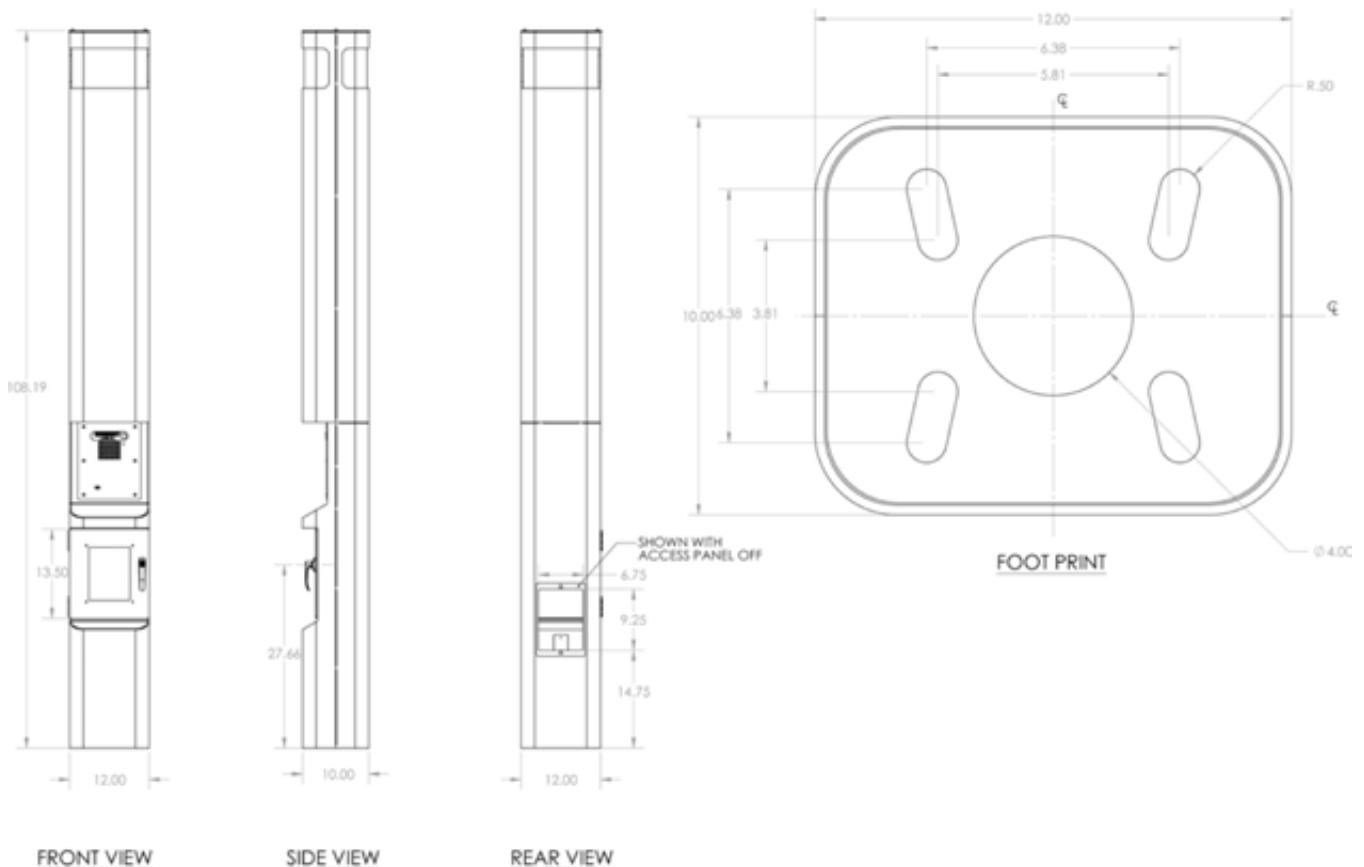

All dimensions are in inches and are provided for reference only.