

ETP-MT/R OP3 – Radius Emergency Phone Tower with Fixed Camera

Description

Talk-A-Phone's ETP-MT/R OP3 Emergency Phone Tower is an ideal security solution for remote and high-risk areas. Standing over nine feet tall, this vandal-resistant tower serves as a great deterrent to crime. An always-lit LED Blue Light mounted atop the tower provides high visibility and gives passers-by a sense of security. Emergency call can be placed with a simple push of a button. At the same time, the LED Blue Light begins to flash, attracting attention to the location. The Emergency Phone faceplate is illuminated at all times for clear visibility during the night.

Talk-A-Phone's ETP-MT/R OP3 Emergency Phone Tower includes a Honeywell fixed day/night CCTV camera inside the tower at average face height for visual verification of caller identity and is often used at university and college campuses, parking facilities, shopping malls, medical centers, industrial campuses, transit facilities and remote areas with no access to power.

Features

- Fixed Honeywell day/night CCTV camera is installed inside the tower above the phone's faceplate, giving an operator a clear view of the caller
- Attention-getting LED Blue Light is included and mounted atop the unit. The LED Blue Light is continuously lit and flashes for duration of a call when "EMERGENCY" button is pressed to draw attention to the unit
- LED Blue Light is housed in a protective polycarbonate housing (except OP4, OP5)
- Emergency Phone faceplate is illuminated at all times by an LED Panel Light
- Vandal-resistant structure and coating designed to resist extreme weather conditions
- A variety of signage, graphics and color choices are available
- ADA-compliant

Specifications

Dimensions (W x D x H):	12.0 x 10.0 x 108.0 in. (305 x 254 x 2743 mm) with 2 in. radius corners
Weight:	340 lbs. (154 kg)
Construction:	0.25 in. steel
Coating:	High-gloss, multi-layer, corrosion-inhibitive system with resistance to UV-fade and graffiti protection
Colors:	Safety Blue is standard. Available in custom colors.
Signage:	3.25 in. high reflective white "EMERGENCY" lettering with wide-angle visibility is standard. Available in custom colors, lettering and graphics.
Lighting:	<div>LED Blue Light: 209 lumens peak, 78 flashes per minute, 70% of initial lumens after 50,000 hours of operation</div> <div>LED Panel Light: Ultra bright LEDs, 50,000 hour lifetime</div>
CCTV Camera:	1/3 in. CCD Day/Night, 0.3 lux color/0.1 lux BW, over 540TVL resolution, backlight compensation, 2.7-13.5mm F1.3, DC auto iris, IR corrected vari-focal lens
Power:	<div>LED Blue Light: 7.8 watts, 120VAC, 12-24VDC/24VAC</div> <div>LED Panel Light: 1.2 watts, 12-120VAC/DC</div> <div>CCTV Camera: 3.5 watts, 11-16VDC/17-28VAC</div>
Compliance:	CSA Certified to UL Standard 60950
Mounting:	Mounts into concrete foundation using included hardware (shipped in advance). Mounting options available for pre-poured parking decks.
Warranty:	5-year warranty on tower (2-year warranty on electronics)



ETP-MT/R OP3 – Radius Emergency Phone Tower with Fixed Camera

Options


ETP-MT/R-OP3 Configuration	Emergency Phone Options	Tower Options
Analog Connectivity	ETP-400 Series Phone	ETP-MT/R- OP3-OP4 includes an arm for mounting your own CCTV dome camera above the tower. ETP-MT/R- OP3-OP5 includes an arm for mounting an AD Speed-Dome Ultra camera above the tower.
IP Connectivity	VOIP-500 Series Phone	ETP-MT/R- OP3-OP-PCS includes accommodations for an ETP-CI cellular interface kit and a PCS-1 Power Charging System when only switching power is available. For use with ETP-400 series emergency phones only. ETP-CI and PCS-1 are purchased separately. ETP-MT/R- OP3-OP-SOLAR includes solar panels and batteries for stand-alone applications when local power is not available.

ETP-MT/R-OP3 tower includes a LED Blue Light, a LED Panel Light, a fixed CCTV camera and an Anchor Bolt Kit. Emergency Phone is purchased separately.

Accessories

Parking Deck Mounting Kit: Order model **ETP-PDMK-4** to mount on pre-poured parking deck.

Dimensional Diagram

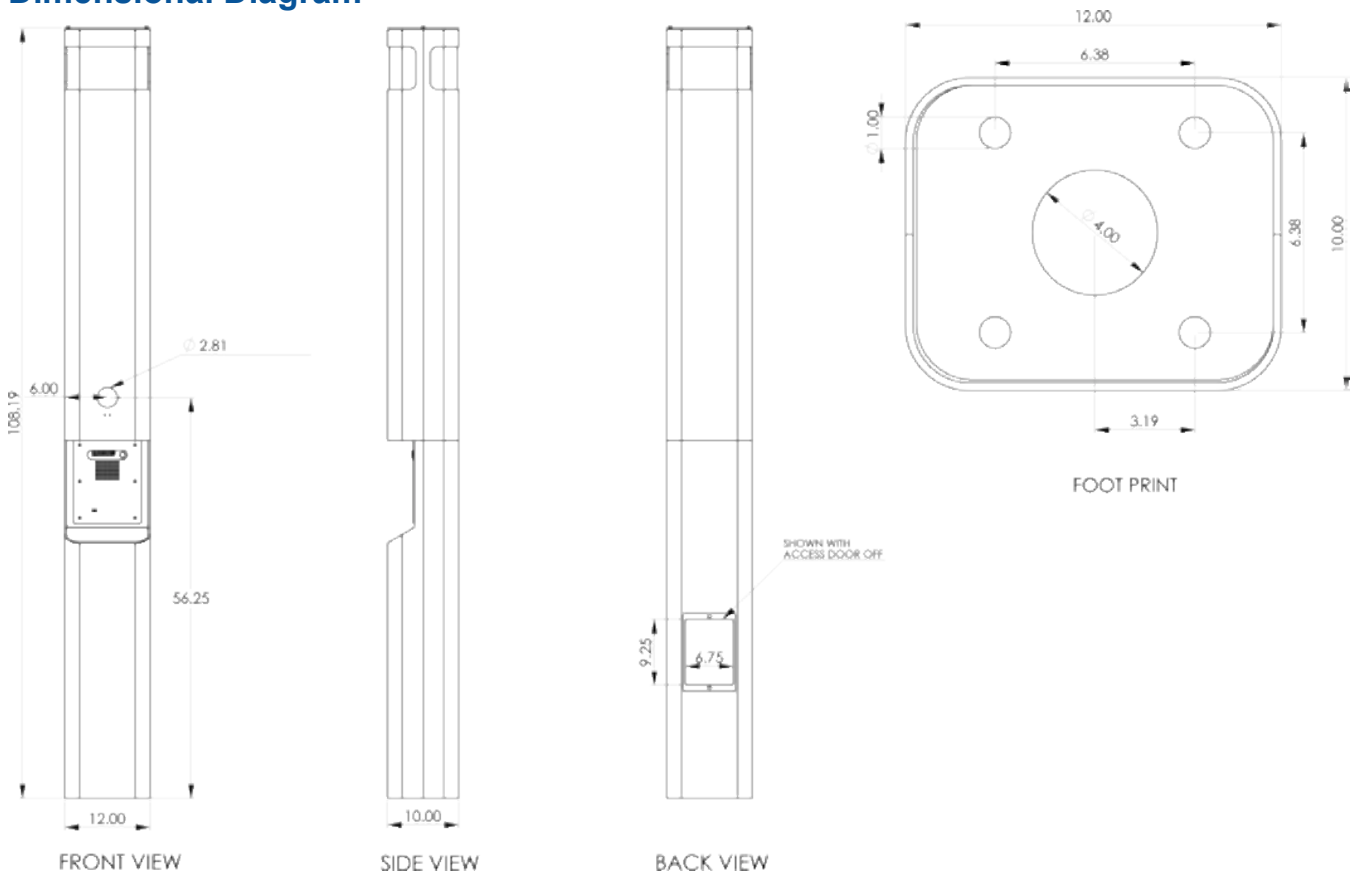

All dimensions are in inches and are provided for reference only.