


Plenum Cable (Station Z)

Unshielded Multiconductor

SPECIFICATIONS

CSA C22.2 No. 214

CSA FT6 (Flame and Smoke Test)

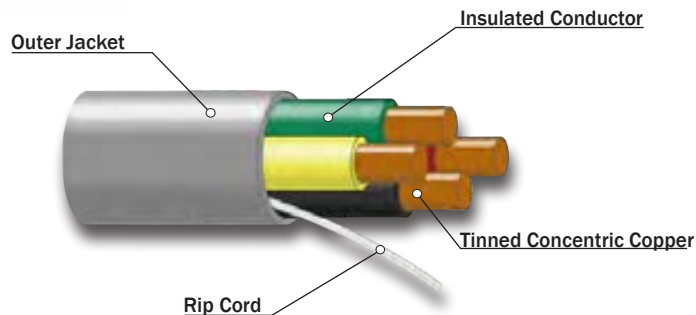

CONSTRUCTION

Conductor: Bare copper

Voltage: 300V

Insulation: Polyvinyl Chloride (PVC)

Options: Various colours for outer jackets

Outer Jacket: 60°C, flame resistant, low smoke Polyvinyl Chloride (PVC), Grey

Product No.	No. of Conductors	AWG Size	Stranding	Insulation Thickness		Outer Jacket Thickness		Nominal Diameter		Cable Weight		Maximum Pulling Tension		Colour Code Chart
				inches	mm	inches	mm	inches	mm					
84-007	4	22	Solid	0.008	0.20	0.015	0.38	0.127	3.23	14.77	22.03	20	9	15
84-023	6	22	Solid	0.008	0.20	0.015	0.38	0.156	3.96	20.81	31.03	31	14	15
84-030	4	22	7/30	0.008	0.20	0.015	0.38	0.148	3.76	16.78	25.02	22	10	1
84-043	8	22	Solid	0.008	0.20	0.015	0.38	0.175	4.45	26.48	39.49	41	19	15

FOR MORE INFORMATION

150 North Murray St.
Trenton, Ontario
(800) 263 . 3322
www.decacables.com

 **ECA CABLES**