


Glacier™ Series Weather Resistant Intensifier3® Bullet Camera with Mount Plate

See Color In Almost Complete Darkness Without IR LEDs

HTINTB8G	2.8 - 12mm auto iris varifocal lens, dark grey housing
HTINTB8GW	2.8 - 12mm auto iris varifocal lens, white housing
HTINTB10G	9 - 22mm auto iris varifocal lens, dark grey housing
HTINTB10GW	9 - 22mm auto iris varifocal lens, white housing

Features

- 1/3" Sony Super HAD II™ CCD
- 650 TV lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Automatic thermostatic sensor
- Minimum illumination 0.00002 lux (Intensifier3® @ 512x)
- Full OSD operation
- Now with Presets: Outdoor, Indoor, Elevator, Lobby, Hallway & Dark
- -40° with Glacier™ heaters
- External controls for zoom & focus
- EZ mount system simplifies installation
- Weather resistant operation
- 12VDC / 24VAC dual voltage operation
- 5 year warranty

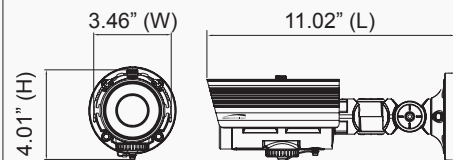

Specifications

Image Sensor	1/3" Sony Super HAD II™ CCD
Resolution.....	650 TV lines
Minimum Illumination.....	CDS Off: 0.15 lux / CDS On: 0.00002 lux
Effective Pixels	768 (H) x 494 (V)
Total Pixels	811 (H) x 508 (V)
TV System.....	NTSC
Scanning Frequency.....	15.734kHz (H) / 59.94Hz (V)
Scanning System.....	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output.....	CVBS: 1.0Vp-p / 75 ohms
Electronic Shutter Speed.....	1/60 sec. – 1/120,000 sec.
OSD.....	Available
WDR.....	On / Off (level adjustable)
Backlight Compensation.....	BLC / HLC / Off
Day/Night.....	Color / BW / Auto
AGC.....	High / Low / Off
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K - 11,000°K)
Intensifier3®.....	Auto / Off (selectable 2x - 512x)
Motion Detection.....	On / Off (8 programmable zones)

Privacy Masking	On / Off (12 programmable zones)
Speco DNR.....	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS.....	On / Off
Sharpness	On / Off (level adjustable)
Flip/Mirror	On / Off
Power Consumption	12VDC, 250mA (heater off) 800mA (heater on) 24VAC, 100mA (heater off) 380mA (heater on)
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Operating Temperature/	
Humidity.....	- 40° F – 140° F / RH 95% max. - 40° F with Glacier™ heaters
Storage Temperature/	
Humidity.....	- 4° F – 140° F / RH 95% max.
Dimensions	3.46" (W) x 4.01" (H) x 11.02" (L)
Weight	3 lbs.



Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation.
Spec Rev. 2/13/13

Optional Accessories



CVCJBB
Round
Junction Box



INTJBS
Square
Junction Box



INTCM
Corner/Pole
Adaptor



PSW4
24VAC
Power Supply



PSDC24
12VDC
Power Supply