



HHDO13D7G 3.6mm fixed lens, dark grey housing

Features


- 1/3" SONY CMOS image sensor
- 2.1M Pixels Full-HD video resolution
- Supports 1080p and 720p
- Simultaneous analog composite video output for easy service & camera installation
- Chameleon Cover™: Snap-on cover converts the housing from standard dark grey to decorator white and can be painted to match any décor*
- 3-axis wall and ceiling mount
- Full OSD operation
- 12VDC / 24VAC dual voltage operation
- Tamper/vandal resistant operation
- Weather resistant operation
- IP66 compliant
- 5 year warranty

Specifications

Image Sensor 1/3" SONY CMOS image sensor
Resolution..... 1920 x 1080p
Minimum Illumination..... 0.5 lux @ F1.2, 0.01 lux (sense-up x60)
Effective Pixels 1944 (H) x 1092 (V), 2.12M pixels
Scanning System..... Progressive
S/N Ratio More than 50dB (AGC off)
Shutter Speed..... Auto, 1/60 sec. – 1/10,000 sec., x2-x30
Sense-Up..... Off / Auto x2-x32
Day & Night Color / BW / Auto / EXT
Lens Type DC / Manual
AGC..... High / Middle / Low / Off
White Balance ATW / AWC - SET / Indoor / Outdoor / Manual
DNR..... High / Middle / Low / Off



Shown with included paintable, snap-on Chameleon Cover™

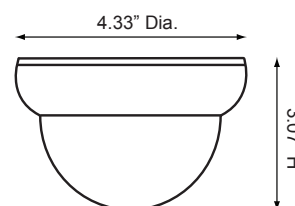

WDR..... High / Middle / Low / Off
BLC / HSBLCL Off / BLC / HSBLCL
Sharpness 1-100 level adjustable
D-Zoom..... x64 (PIP)
Motion Detection..... 3 zone
Privacy..... 8 zone
Video Output..... HD-SDI, CVBS simultaneously
Power Supply 12VDC / 24VAC dual voltage operation
(power supply not included)
Power Consumption 12VDC, 250mA / 24VAC, 150mA
Operating Temperature..... -4° F – 140° F
Dimensions..... 3.07" (H) x 4.33" (Dia.)
Weight 1.54 lbs.

Optional Accessories



HDFO
Fiber Optic
3G SDI Extender



HDR
HD-SDI
Repeater



HDS1T4
HD-SDI
4 Channel Splitter



PSW5
12VDC
Power Supply



PSW4
24VAC
Power Supply

* Chameleon Cover™ is for indoor use only. It must be painted with waterproof paint if used outdoors.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

Rev. 1/18/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com