

Intensifier3® Series Indoor/Outdoor Bullet Camera


See Color In Almost Complete Darkness Without IR LEDs

HTINTB8	2.8 - 12mm auto iris varifocal lens, dark grey housing
HTINTB8W	2.8 - 12mm auto iris varifocal lens, white housing
HTINTB9	5 - 50mm auto iris varifocal lens, dark grey housing
HTINTB9W	5 - 50mm auto iris varifocal lens, white housing
HTINTB10	9 - 22mm auto iris varifocal lens, dark grey housing
HTINTB10W	9 - 22mm auto iris varifocal lens, white housing

Features

- 1/3" Sony Super HAD II™ CCD
- 650 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Minimum illumination 0.00002 lux (Intensifier3® @ 512x)
- Full OSD operation
- Now with Presets: Outdoor, Indoor, Elevator, Lobby, Hallway & Dark
- Anti-moisture glass and circuitry eliminates fog or condensation under any weather condition external controls for zoom & focus
- S/N Ratio more than 52dB (weight on)
- EZ mount system simplifies installation
- Relay outputs for motion detection
- Weather resistant operation
- IP66 compliant
- 12VDC / 24VAC dual voltage operation
- 5 year warranty

**INT
3**

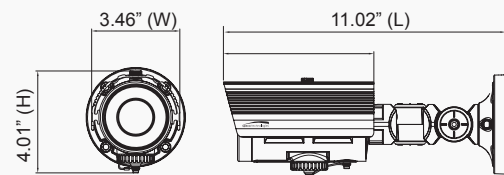

Specifications

Image Sensor	1/3" Sony Super HAD II™ CCD	White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K – 11,000°K)
Resolution	650 TV lines	Intensifier3®	Auto / Off (selectable 2x - 512x)
Minimum Illumination	CDS off: 0.15 lux / CDS on: 0.00002 lux	Motion Detection	On / Off (8 programmable zones)
Effective Pixels	768 (H) x 494 (V)	Privacy Masking	On / Off (12 programmable zones)
Total Pixels	811 (H) x 508 (V)	Speco DNR	On / Off (level adjustable)
TV System	NTSC	Digital Zoom	On / Off (1x - 16x)
Scanning Frequency	15.734kHz (H) & 59.94Hz (V)	DIS	On / Off
Scanning System	2:1 interlace	Sharpness	On / Off (level adjustable)
Synchronization	Internal	Flip/Mirror	On / Off
S/N Ratio	More than 52dB	Power Consumption	12VDC, 400mA / 24VAC, 170mA
Video Output	CVBS: 1.0Vp-p / 75 ohms	Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Electronic Shutter Speed	1/60 sec. – 1/120,000 sec.	Operating Temperature	-4° F – 140° F
OSD	Available	Dimensions	3.46" (W) x 4.01" (H) x 11.02" (L)
WDR	On / Off (level adjustable)	Weight	3 lbs.
Backlight Compensation	BLC / HLC / Off		
Day/Night	Color / BW / Auto		
AGC	High / Low / Off		

Optional Accessories



CVCJBB
Bullet Camera
Junction Box



INTJBS
Square
Junction
Box



INTCM
Corner/Pole
Adaptor



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply



Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation.
Rev. 2/22/13