

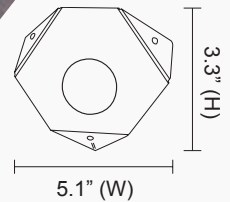
960H Vandal Resistant Corner Mount Color Camera

CVC607CMT 3.6mm lens - optional lenses available, grey housing

Features

- 1/3" Sony Super HAD II™ CCD
- 700 TV lines of resolution
- Vandal resistant 90° corner mount camera
- Heavy duty housing is built to withstand blows from a 10 lb. sledgehammer
- Also available in brass housing
- 5 year warranty

960

Specifications

Image Sensor	1/3" Sony Super HAD II™ CCD
Resolution.....	700 TV lines
Minimum Illumination.....	0.001 lux (sense-up on)
Effective Pixels	976 (H) x 494 (V)
Total Pixels	1020 (H) x 508 (V)
Electronic Shutter	1/60 sec. – 1/100,000 sec.
S/N Ratio	More than 52dB
Video Output.....	1.0Vp-p / 75 ohms
Power Consumption	230mA
Power Supply	12VDC, 500mA (power supply not included)
Operating Temperature.....	14° F – 122° F
Housing	16 gauge steel
Dimensions.....	5.1" (W) x 3.3" (H)
Weight	1.5 lbs.

Optional Accessory



PSW5
 12VDC
 Power Supply

Optional Lenses

CVC607CMT2.2.....	2.2mm lens
CVC607EXCM2.5.....	2.5mm lens
CVC607EXCM2.5B (brass housing)	2.5mm lens

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 1/16/14