


Color Conical Pinhole Bullet Camera

CVC622PH 4.3mm conical pinhole lens, black housing

Features

- Pinhole lens allows camera to view through a 1/16" hole
- Conical shape is perfect to use with thicker materials like ceiling tiles or sheet rock
- Miniature size is easy to conceal
- Miniature mount included
- 5 year warranty

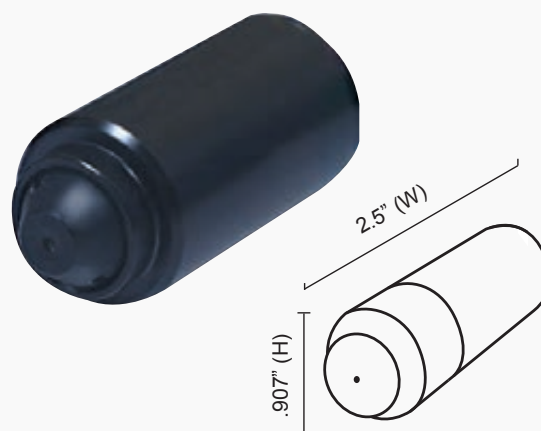

Specifications

Image Sensor	1/3" CCD
Resolution.....	380 TV lines
Minimum Illumination.....	1 lux
Effective Pixels	512 (H) x 492 (V)
Electronic Shutter Speed.....	Auto: 1/60 sec. - 100,000 sec.
Output.....	RCA with BNC adapter, power - DC jack
Scanning Frequency.....	15.75kHz (H) / 60Hz (V)
Scanning System.....	EIA standard 525 TV lines, 60 fields per sec.
S/N Ratio	More than 48dB
Video Output.....	1.0Vp-p / 75 ohms
Power Consumption	130mA
Power Supply	12VDC (UL & CSA listed power supply included)
Operating Temperature/	
Humidity.....	-20° F – 122° F / within 95% RH
Dimensions.....	2.5" (W) x .907" (H) x .907" (L)
Weight	2 oz.



Speco Technologies is constantly developing and improving products.
We reserve the right to modify product design and specifications without notice
and without incurring any obligation.
Spec Rev. 2/22/13