

For Your Perfect Full HD Deliverables

The SMT-4031/3231 are 40"/32" monitors with Full HD a native 1920 x 1080 panel resolution optimized for CCTV applications. Benefiting from the latest onboard LED panel technology that offers excellent picture quality along with a fast 8ms response time. Offering 600TV lines high resolution and various video output via HDMI, DVI, VGA and component (CVBS common), the SMT-4031/3231 is the perfect professional security monitor.

SMT-4031/3231

40"/32" LED Monitor



- Super high resolution 600TV lines
- High contrast ratio 5000 : 1
- Fast response time 8ms
- HDMI, DVI, VGA, and component (CVBS common) video output
- Built-in speaker
- Ethernet / RS-232C remote control
- Magicinfo lite : scheduling function auto play function







Dimensions

Unit : mm (inch)

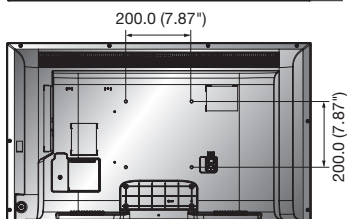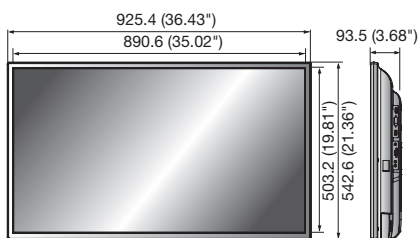

SMT-4031

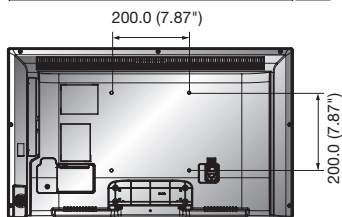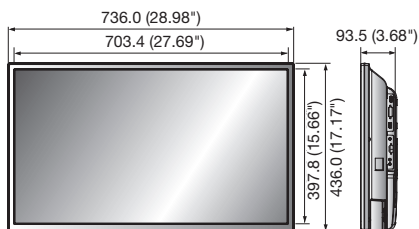


SMT-3231

Specifications

		SMT-4031	SMT-3231
DISPLAY			
Type		LED	
Screen Size		40"	32"
Max. Resolution		1,920 x 1,080	
Brightness		350cd/m ²	
Contrast Ratio		5,000 : 1	
Aspect Ratio		16 : 9	
Viewing Angle (H/V)		178° / 178°	
Display Color		16.7million	
Response Time		8ms (G to G)	
Video System		NTSC / PAL	
Panel Life		50,000hours	
Filter Type		3D combfilter	
INTERFACE			
Video	Connector	VGA, DVI, HDMI, Component (CVBS common)	
	Connector	Analogue D-sub (15 pin), DVI-D	
	Input Signal	0.7Vp-p ±5%	
RGB / DVI	Available Format	640 x 480@60Hz/66Hz/72Hz/75Hz (VGA), 720 x 400@70Hz, 800 x 600@56Hz/60Hz/72Hz/75Hz (SVGA), 832 x 624@75Hz, 1,024 x 768@60Hz/70Hz/75Hz (XGA), 1,152 x 864@75Hz, 1,280 x 720@60Hz, 1,280 x 800@60Hz,1,280 x 1,024@60Hz/75Hz (SXGA), 1,360 x 768@60Hz, 1,440 x 900@60Hz, 1,600 x 900@60Hz, 1,680 x 1,050@60Hz, 1,920 x 1,080@60Hz	
HDMI	Connector	HDMI	
	Available Format	640 x 480p@60Hz, 720 x 480p@60Hz, 720 x 576p@50Hz, 1,280 x 720p@50Hz/60Hz, 1,920 x 1,080i@60Hz, 1,920 x 1,080p@60Hz	
Audio	Connector	RS232C (L/R)	
	Output Signal	Loop-through line level (PC only), Speakers : 2 x 5W	
Application Support		Remote controller	
ON SCREEN DISPLAY			
Functions		VESA™ DPM compatible	
Language		Chinese (Traditional, Simplified), English, French, German, Italian, Japanese, Korean, Polish, Portuguese, Russian, Spanish, Swedish, Turkish	
GENERAL			
Electrical	Input Voltage	100 ~ 240V AC (50/60Hz)	
	Power Consumption	110W	77W
Environmental	Operating Temperature	0 ~ +40°C (+32°F ~ +104°F)	
	Operating Humidity	10% ~ 80% (Non-condensing)	
Mechanical	Dimensions with Stand (WxHxD)	925.4 x 612.6 x 311.0mm (36.43" x 24.12" x 12.24")	736.0 x 506.0 x 311.0mm (23.98" x 19.92" x 12.24")
	Dimensions without Stand (WxHxD)	925.4 x 542.6 x 93.5mm (36.43" x 21.36" x 3.68")	736.0 x 436.0 x 93.5mm (23.98" x 17.17" x 3.68")
	Bezel Size	17.4mm (0.69") / Bottom 20.4mm (0.8")	16.3mm (0.64") / Bottom 20.4mm (0.8")
	Weight	9.8Kg (20.61 lb)	6.4Kg (14.11 lb)
	Cabinet Color	Black	
	Rack Mounts	Optional	
	VESA Mounts Interface	200 x 200mm	
Accessory		SBM-320ST (Optional)	

Accessories (Optional)

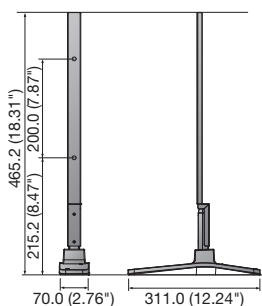

Foot Stand SBM-320ST



The Eco mark represents Samsung Techwin's will to create environment-friendly products, and indicates that the product satisfies the EU RoHS Directive.

DISTRIBUTED BY



SAMSUNG TECHWIN CO., LTD.

6, Pangyo-ro 319beon-gil, Bundang-gu, Seongnam-si, Gyeonggi-do, SEOUL 463-400 Rep. of KOREA
Tel : +82-70-7147-8741~8749, 8752~8760 Fax : +82-31-8018-3745 www.samsungsecurity.com www.samsungcctv.com
COPYRIGHT BY SAMSUNG TECHWIN. ALL RIGHT RESERVED

SAMSUNG TECHWIN AMERICA INC.
100 Challenger Rd. Suite 700 Ridgely Park, NJ 07660
Toll Free : +1-877-213-1222 Direct : +1-201-325-6920
Fax : +1-201-373-0124

SAMSUNG TECHWIN EUROPE LTD.
2nd Floor, No. 5 The Heights, Brooklands, Weybridge, Surrey, KT13 0NY, UK
Tel : +44-1932-82-6700 Fax : +44 1932 82 6701

SHANGHAI SAMSUNG TECHWIN CO., LTD.
32F, Bld B, International Business Center, No. 391 Guiping Rd., Shanghai, China, 200233
Tel : +86-21-5427-1155 Fax : +86-21-5423-5122


SAMSUNG TECHWIN