

SRN-470D

4CH Network Video Recorder




Key Features

- Up to 4CH, 3MP supported
- H.264, MJPEG, MPEG-4 multiple codec
- 64Mbps network camera recording
- 1 HDD
- HDMI/VGA local monitor
- e-SATA storage supported
- DVD-RW

Dimensions

Unit : mm (inch)

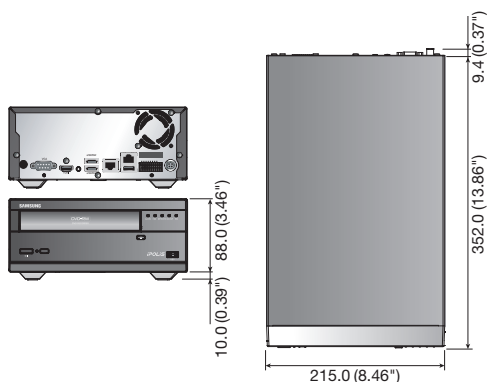

SRN-470D		
DISPLAY		
N/W Camera	Inputs	Up to 4CH
	Resolution	VGA (640 x 480) / SVGA (800 x 600) / 4CIF (704 x 480) / 1.3M (1280 x 1024) / 2M (1920 x 1080) / 3M (2048 x 1536)
	Protocols	Samsung
Live	Multi Screen Display	1 / 4, Sequence
PERFORMANCE		
Operating System	Embedded	Linux
Recording	Compression	H.264, MPEG-4, MJPEG
	Recording Bit Rate	64Mbps
	Resolution	4CIF (704 x 480) / 1.3M (1280 x 1024) / 2M (1920 x 1080) / 3M (2048 x 1536)
	Mode	Manual, Schedule (Continuous / Event), Event (Pre / Post)
	Overwrite Modes	Selectable (Stop / Continuous)
	Pre-alarm	Up to 15sec (5,10,15sec) *4CIF standard resolution
Search & Playback	Post-alarm	Up to 6hour (5, 10, 20, 30sec, 1, 3, 5, 10, 20min, 1, 2, 3, 4, 5, 6hour)
	Playback Speed	120fps (Up to 4CH)
	Resolution	4CIF (704 x 480) / 1.3M (1280 x 1024) / 2M (1920 x 1080) / 3M (2048 x 1536)
	Search Mode	Date/time, Event, Back up (*All search included preview function)
Network	Playback Function	Fast forward / backward, Slow forward / backward, Step forward / backward
	Ethernet	Gigabit Ethernet x 2
	Transmission Speed	Up to 48Mbps, Unlimited (48M) / 2 / 1.5 / 1Mbps / 800 / 600 / 500 / 400 / 300 / 200 / 100 / 50kbps
	Bandwidth Control	Automatic
	Max. Remote Users	Search 3 / Live unicast 10 / Live multicast 20
Storage	Protocol Support	TCP/IP, DHCP, PPPoE, SMTP, NTP, HTTP, DDNS, RTP, RTSP
	Monitoring	SmartViewer, Webviewer
	Internal HDD	Up to 1 SATA HDD
	External (e-SATA Interface)	Up to 2 expansion bay (*Model : SVS-5R)
	DVD Writer (Back up)	Yes
Security	USB (Back up)	2 USB ports
	File Format (Back up)	BU (NVR player), EXE (Include player)
	Password Protection	1 Admin, 10 Group, 20 User per 1 group, User can be assigned authority for function
INTERFACE	Data Authentication	Watermark
	Monitors	VGA: Analogue RGB 1280 x 1024(60Hz) resolution HDMI: 720p/1080p(60Hz) resolution
Audio	Input	N/A (Network audio support, up to 4CH)
	Output	RCA x 1
Alarm	Compression	G.711, G.723.1, G.726
	Input	Terminal 4 inputs (NO/NC)
	Output	Terminal 2 relay outputs (NO/NC)
Connections	Remote Notification	Notification via e-mail
	Ethernet	2 RJ-45 10/100/1000 Base-T
	USB	USB 2.0, 2 ports
Dome Protocols	eSATA	2 ports
	Application Support	Mouse, Remote controller
GENERAL	Supported PTZ Cameras	Samsung network products (Network PTZ)
	Input Voltage / Current	12V DC adaptor, 4A, 100 ~ 250V AC, 50/60Hz, 1.2A
Electrical	Power Consumption	Max. 36W (With 1x HDD)
	Operating Temperature	+0°C ~ +40°C (+32°F ~ +104°F)
Environmental	Operating Humidity	20% ~ 85% RH
	Dimensions (WxHxD)	215.0 x 88.0 x 352.0mm (8.46" x 3.46" x 13.86")
Mechanical	Weight (1x Hard Disks)	Approx. 3.7Kg (8.16 lb)
	Language	Korean, Japanese, Chinese, English, French, German, Spanish, Italian, Russian, Polish, Czech, Turkish, Netherlands, Portuguese, Swedish, Danish, Thai, Romanian, Serbian, Croatian, Hungarian, Greek (22 Language)

* The latest product information / specification can be found at www.samsungsecurity.com