

SCD-3080/2080

1/3" High Resolution Vari-focal Dome Camera



SCD-3080/2080

SCD-3080B/2080B




Key Features

- High resolution of 600TV lines, 700TV lines (B/W)
- Min. illumination 0.3Lux@F1.2 (Color), 0.01Lux (B/W) : SCD-3080
0.15Lux@F1.2 (Color), 0.001Lux (B/W) : SCD-2080
- 3.9x V/F lens (2.8 ~ 11mm) : SCD-3080
3.6x V/F lens (2.8 ~ 10mm) : SCD-2080
- WDR, VPS, intelligent Video : SCD-3080
- True Day / Night (ICR) : SCD-3080/2080, MD, SSNRIII
- Coax : Pelco-C (Coaxitron)
- Dual power, 24V AC & 12V DC

Dimensions

Unit : mm (inch)

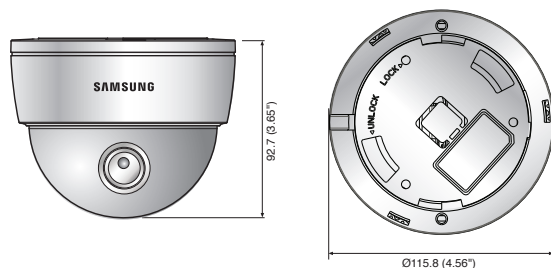

Technical Specifications

	SCD-3080N/2080N	SCD-3080P/2080P
VIDEO		
Imaging Device	1/3" Super HAD CCD (Double scan) : SCD-3080, 1/3" Super HAD CCD : SCD-2080	
Total Pixels	811(H) x 508(V)	795(H) x 596(V)
Effective Pixels	768(H) x 494(V)	752(H) x 582(V)
Scanning System	2 : 1 Interlace	
Synchronization	Internal / Line lock	
Frequency	H : 15.734KHz / V : 59.94Hz	H : 15.625KHz / V : 50Hz
Horizontal Resolution	Color : 600TV lines, B/W : 700TV lines	
Min. Illumination	Color : 0.3Lux@F1.2 (50IRE), 0.0006Lux (Sens-up, 512x) : SCD-3080	
	0.15Lux@F1.2 (50IRE) : 0.0003Lux (Sens-up, 512x) : SCD-2080	
	B/W : 0.01Lux@F1.2 (50IRE), 0.00002Lux (Sens-up, 512x) : SCD-3080	
	0.001Lux@F1.2 (50IRE), 0.000002Lux (Sens-up, 512x) : SCD-2080	
S / N Ratio	52dB (AGC off, Weight on)	
Video Output	CVBS : 1.0 Vp-p / 75Ω composite	
LENS		
Focal Length (Zoom Ratio)	2.8 ~ 11mm (3.9x) : SCD-3080, 2.8 ~ 10mm (3.6x) : SCD-2080	
Max. Aperture Ratio	1 : 1.2(Wide) ~ 2.8(Tele)	
Angular Field of View	H : 94°(Wide) ~ 26°(Tele) / V : 67°(Wide) ~ 20°(Tele) : SCD-3080	
	H : 94.4°(Wide) ~ 28°(Tele) / V : 69.2°(Wide) ~ 21°(Tele) : SCD-2080	
Min. Object Distance	0.2m (0.66ft)	
Lens Type	DC auto iris	
Mount Type	Board type	
PAN / TILT		
Pan Range	0° ~ 340° : SCD-3080, 0° ~ 352° : SCD-2080	
Tilt Range	0° ~ 73°	
Rotate Range	0° ~ 340° : SCD-3080, 0° ~ 348° : SCD-2080	
OPERATIONAL		
On Screen Display	English, Japanese, Spanish, French, Portuguese, Taiwanese, Korean	English, French, German, Spanish, Italian, Chinese, Russian, Polish, Czech, Romanian, Serbian, Swedish, Danish, Turkish, Portuguese
Camera Title	Off / On (Displayed 15 characters)	
Day & Night	Auto (ICR) / External / Color / B/W : SCD-3080	
	Auto (ICR) / Color / B/W : SCD-2080	
Backlight Compensation	Off / User BLC / HLC / SSDR / WDR : SCD-3080, BLC / HLC / Off : SCD-2080	
Wide Dynamic Range	128x (52dB) : SCD-3080N	160x (52dB) : SCD-3080P
Contrast Enhancement	SSDR (Off / On)	
Digital Noise Reduction	SSNRIII (Off / On)	
Digital Image Stabilization	Off / On	
Motion Detection	Off / On (8 programmable zones)	
Privacy Masking	Off / On (12 programmable zones)	
Sens-up (Frame Integration)	2x ~ 512x	
Gain Control	Off / Low / High	
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700K° ~ 11,000K°)	
Electronic Shutter Speed	1/60 ~ 1/120,000sec	1/50 ~ 1/120,000sec
Digital Zoom	Off / On (1x ~ 16x)	
Flip	Vertical / Horizontal	
Profile	Basic / Day & Night / Backlight / ITS / Indoor / User : SCD-3080	
VPS	Off / On : SCD-3080	
Intelligent Video	Fixed / Moved / Area / Fence / Tracking / Detection / Counting : SCD-3080	
PIP	Off / On : SCD-3080	
Alarm	1 Out : SCD-3080	
Communication	Coaxial control	
Protocol	Coax : Pelco-C (Coaxitron)	
ENVIRONMENTAL		
Operating Temperature / Humidity	-10°C ~ +50°C (+14°F ~ +122°F) / Less than 90% RH	
ELECTRICAL		
Input Voltage	Dual (24V AC & 12V DC ±10%)	
Power Consumption	Max. 3.5W	
MECHANICAL		
Color / Material	Ivory or Black / Plastic	
Dome Cover	Clear	
Dimensions (WxH)	Ø115.8 x 92.7mm (Ø4.56" x 3.65")	
Weight	365g (0.8 lb) : SCD-3080, 345g (0.76 lb) : SCD-2080	
Also available in black : SCD-3080R/2080R		

Also available in black : SCD-3080B/2080B