

16CH/8CH 960H Real-time Compact DVR

SRD-1642/842

16CH/8CH 960H Real-time Compact Design Coaxial DVR

- 16CH/8CH 960H Real-time DVR
 - Up to 480(N) / 400(P)fps recording rate (SRD-1642)
 - Up to 240(N) / 200(P)fps recording rate (SRD-842)
- Easy user interface, common across all Samsung DVRs
 - GUI / Search / Back up / Set-up
- Set independently for each channel - REC / Quality / Resolution
- Privacy mask support each channel (4ea)
- Convenient network monitoring
 - Web viewer, SSM, SmartViewer, iPOLiS smart phone app
- USB (2ports) back up




SRD-1642/842



Dimensions

Unit : mm (inch)

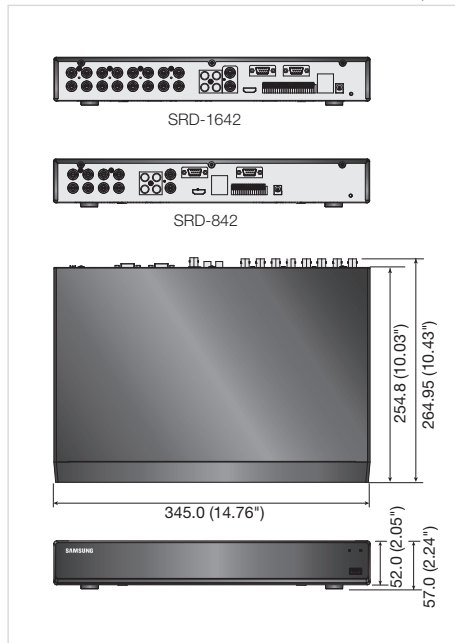

		SRD-1642	SRD-842
DISPLAY			
Video	Inputs	16 composite video 0.5~1 Vpp, 75 ohm	8 composite video 0.5~1 Vpp, 75 ohm
	Resolution	NTSC : 960 x 480, 720 x 480 / PAL : 960 x 576, 720 x 576	
Live	Frame Rate	NTSC : 480fps / PAL : 400fps	NTSC : 240fps / PAL : 200fps
	Resolution	NTSC : 720 x 480 / PAL : 720 x 576	
	Multi Screen Display	1 / 4 / 6 / 8 / 9 / 13 / 16 / Sequence / PIP	1 / 4 / 6 / 8 / Sequence / PIP
PERFORMANCE			
Operating System	Embedded	Linux	
	Compression	H.264	
Recording	Record Rate	NTSC : Up to 480fps@960 x 480 / PAL : Up to 400fps@960 x 576 NTSC : Up to 480fps@704 x 480 / PAL : Up to 400fps@704 x 576 NTSC : Up to 480fps@704 x 240 / PAL : Up to 400fps@704 x 288 NTSC : Up to 480fps@352 x 240 / PAL : Up to 400fps@352 x 288	NTSC : Up to 240fps@960 x 480 / PAL : Up to 200fps@960 x 576 NTSC : Up to 240fps@704 x 480 / PAL : Up to 200fps@704 x 576 NTSC : Up to 240fps@704 x 240 / PAL : Up to 200fps@704 x 288 NTSC : Up to 240fps@352 x 240 / PAL : Up to 200fps@352 x 288
	Mode	NTSC : Manual, Schedule (Continuous / Event), Event (Pre / Post) PAL : Manual, Schedule (Continuous / Event), Event (Pre / Post)	
	Event	Video loss, Motion (Level 1 ~ 10), Alarm	
	Overwrite Modes	Continuous, Selectable (Stop / Continuous)	
	Pre-alarm	Up to 5sec	
	Post-alarm	Up to 6hour (5,10, 20, 30sec, 1, 3, 5, 10, 20min, 1, 2, 3, 4, 5, 6hour)	
Search & Playback	Search Mode	Date/Time, Event (Alarm / Motion), Back up, POS (*All search include preview function)	
	Playback Function	Fast forward / backward (2x, 4x, 8x, 16x, 32x, 64x) *Backward play with i-frame only Slow forward / backward (1/2x, 1/4x, 1/8x)	
Network	Transmission Speed	CIF (NTSC : 480fps, PAL : 400fps)	
	Bandwidth	Up to 32Mbps, Unlimited (8M) / 2 / 1.5 / 1Mbps / 800 / 600 / 500 / 400 / 300 / 200 / 100 / 50kbps	Up to 16Mbps, Unlimited 2 / 1.5 / 1Mbps / 800 / 600 / 500 / 400 / 300 / 200 / 100 / 50kbps
	Bandwidth Control	Automatic	
	Stream	H.264 (CIF)	
Smart Phone	Max. Remote Users	4 persons (Search up to 2, Live unicast / Live multicast available)	
	Protocol Support	TCP/IP, DHCP, PPPoE, SMTP, NTP, HTTP, DDNS, RTP, RTSP, SNMP	
	Monitoring	Webviewer, CMS (SmartViewer, Net-I)	
	Platform	Android, iOS	
Storage	Protocol Support	RTSP, RTSP, HTTP, CGI	
	Max. Remote Users	Live 1	
Internal HDD	Up to 2 SATA HDDs		
	USB (Back up)	2 USB ports	
File Format (Back up)	BU (DVR player), EXE (Include player), AVI		
	Password Protection	1 Admin, 10 Group, 10 User per 1 group	
Security	Data Authentication	Watermark	
INTERFACE			
Monitors	VGA	1 VGA (1280 x 720, 1280 x 1024, 1920 x 1080)	
	HDMI	1 HDMI (1280 x 720, 1280 x 1024, 1920 x 1080)	
Audio	Spot Composite	Digital spot (1CH) *Included OSD on screen, multi mode support	
	Inputs / Output	4CH line in / 1CH line out	
	Compression	G.711	
	Sampling Rate	8KHz	
Alarm	Inputs / Output	Terminal 16 inputs (NO/NC) / Terminal 2 relay outputs (NO), Rating : 24V DC / 1A, 125V AC / 0.5A	Terminal 8 inputs (NO/NC) / Terminal 2 relay outputs (NO), Rating : 24V DC / 1A, 125V AC / 0.5A
	Remote Notification	Notification via e-mail	
Connections	Ethernet	1 RJ-45 10/100 Base-T	
	Serial Interface	RS-485 (Half) for PTZ, System keyboard, RS-232 support for POS interface (VSI-pro)	
	USB	USB 2.0, 2 ports (Front)	
	Application Support	Mouse, Remote controller	
	Protocol Support	Samsung-T/E, Pelco-D/P, Panasonic, Phillips, AD, DIAMOND, ERNA, KALATEL, VCL TP, VICON, ELMO, GE PTZ control via coaxial cable [Samsung CCVC, Pelco-C (Coaxitron)]	
GENERAL			
Electrical	Input Voltage / Current	12V DC adaptor, 4A, 100 ~ 250V AC, 50/60Hz, 48watt	
	Power Consumption	Max. 19W (With 1x HDD)	
Environmental	Operating Temperature	+0°C ~ +40°C (+32°F ~ +104°F)	
	Operating Humidity	20% ~ 85% RH	
Mechanical	Dimensions (WxHxD)	345.0 x 52.0 x 254.8mm (14.76" x 2.05" x 10.03")	
	Weight (With hard disks)	Approx. 2.38Kg (5.25 lb)	Approx. 2.31Kg (5.09 lb)
	Rack Mount Kit	2ea	
Language		Korean, Japanese, Chinese (Traditional), English, French, German, Spanish, Italian, Russian, Polish, Czech, Turkish, Netherlands, Portuguese, Swedish, Danish, Thai, Romanian, Serbian, Croatian, Hungarian, Greek, Finnish, Norwegian, Taiwanese (25 Language)	



The Eco mark represents Samsung Techwin's will to create environment-friendly products, and indicates that the product satisfies the EU RoHS Directive.

DISTRIBUTED BY



SAMSUNG TECHWIN CO., LTD.

6, Pangyo-ro 319beon-gil, Bundang-gu, Seongnam-si, Gyeonggi-do, SEOUL 463-400 Rep. of KOREA
Tel : +82-70-7147-8741 ~ 8749, 8752 ~ 8760 Fax : +82-31-8018-3745 www.samsungsecurity.com www.samsungcctv.com
COPYRIGHT BY SAMSUNG TECHWIN. ALL RIGHT RESERVED

SAMSUNG TECHWIN AMERICA Inc.
100 Challenger Rd. Suite 700 Ridgely Park, NJ 07660
Toll Free : +1-877-213-1222 Direct : +1-201-325-6920
Fax : +1-201-373-0124

SAMSUNG TECHWIN EUROPE LTD.
2nd Floor, No. 5 The Heights, Brooklands, Weybridge,
Surrey, KT13 0NY, UK
Tel : +44-1932-82-6700 Fax : +44-1932-82-6701

SHANGHAI SAMSUNG TECHWIN CO., LTD.
32F, Bld B, International Business Center,
No. 391 Guiping Rd., Shanghai, China, 200233
Tel : +86-21-5427-1155 Fax : +86-21-5423-5122



SAMSUNG TECHWIN

Design and specifications are subject to change without notice.