 




0915 034 101/... M



AS-Interface cordset, double-ended, M12 male connector and M12 female connector with self-locking threaded joint.



AS-Interface Accessories

Technical Data

Environmental

Degree of protection IP 67
Temperature range -25°C / +80°C

Materials

Housing / Molded body TPU, self-extinguishing
Insert TPU, self-extinguishing
Contact Male connector: CuZn, prenickel and 0.8 microns gold-plated
Female connector: CuZn, prenickel and 0.3 microns gold-plated
Receptacle shell / knurled screw/ nut / hexagon screw/nut / sleeve CuZn, nickel-plated
O-ring FKM (only female connector)

Electrical data


Nominal current at 40°C 4 A
Nominal voltage 240 V
Rated voltage 250 V
Test voltage 2.0 kV eff. / 60 s
Insulation resistance > 10⁹ Ω
Pollution degree 3

Cable specification

PUR/PVC - cable-no. 34
Further information please see chapter "Cable specifications"

Pin Assignments

4-Poles

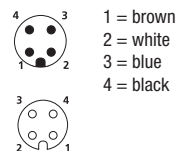

Part Number	Poles	Out Jacket	Standard Cable Lengths
0915 034 101/...M	4	PUR	1 M / 3 M / 5 M



The application of these products in harsh environments should always be checked before use.
Specifications subject to alteration.