



# Be Certain with Belden

## Profibus Signal Cables

0975 254 101 | 0975 254 102 | 0975 254 103



0975 254 101/...M

Double-ended cord set, M12 male connector to M12 female connector, 5 poles, B-coding.

0975 254 102/...M

Single-ended cord set, M12 male connector, 5 poles, B-coding.

0975 254 103/...M

Single-ended cord set, M12 female connector, 5 poles, B-coding.

0975 254 104



0975 254 104/...M

Double-ended cord set, M12 female connector, 5 poles, B-coding to SUBD male connector, 9 poles with switch-on terminating resistor.

0975 254 105




0975 254 105/...M

Double-ended cord set, M12 male connector, 5 poles, B-coding to SUBD male connector, 9 poles with switch-on terminating resistor.

### Pin Assignment

M12 male/female connector, 5 poles

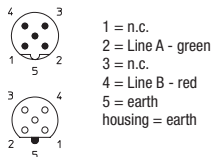

Part Number	Standard Cable Lengths	UL	RoHS	REACH	CSA	CE
0975 254 101/...M	0.3 M   0.6 M   1 M   2 M   3 M   5 M   10 M   15 M   20 M   25 M	UL	RoHS	REACH	CSA	CE
0975 254 102/...M	1 M   3 M   5 M   10 M   15 M	UL	RoHS	REACH	CSA	CE
0975 254 103/...M	1 M   3 M   5 M   10 M   15 M	UL	RoHS	REACH	CSA	CE
0975 254 104/...M	1 M   2 M   3 M   5 M	RoHS	REACH	CSA	CE	
0975 254 105/...M	1 M   2 M   3 M   5 M	RoHS	REACH	CSA	CE	