





Access Floor Grounding Clamp



Type GPQC

- Bond mesh common bonding network (MCBN) conductors to each other and bond the access floor pedestals to the conductors
- Specifically designed to bond perpendicular MCBN conductors per TIA-942
- Bond to the pedestal with a single bolt to simplify installation
- Accommodate conductors from #6 – 1/0 AWG, minimizes inventory requirements
- Bond round and square access floor pedestals for greater flexibility

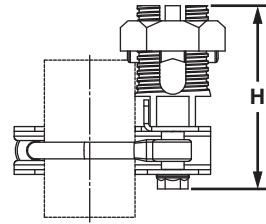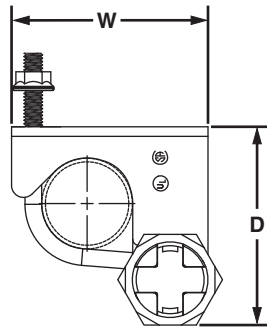

| Part Number | Round Pedestal (In.) | Square Pedestal (In.) | MCBN Conductor Size Range AWG (mm ²) | Figure Dimensions In. (mm) | | | Std. Pkg. Qty. | Std. Ctn. Qty. |
|-------------|----------------------|-----------------------|--|----------------------------|--------------|-------------|----------------|----------------|
| | | | | D | W | H | | |
| GPQC07-1/0 | 3/4 – 7/8 | — | #6 SOL – 1/0 STR (16 – 50) | 4.25 (108.0) | 3.38 (85.9) | 3.19 (81.0) | 1 | 10 |
| GPQC10-1/0 | 1 – 1 1/8 | 7/8 | #6 SOL – 1/0 STR (16 – 50) | 4.19 (106.4) | 3.38 (85.9) | 3.19 (81.0) | 1 | 10 |
| GPQC12-1/0 | 1 1/4 | — | #6 SOL – 1/0 STR (16 – 50) | 4.53 (115.1) | 3.44 (87.4) | 3.19 (81.0) | 1 | 10 |
| GPQC15-1/0 | 1 1/2 | — | #6 SOL – 1/0 STR (16 – 50) | 4.47 (113.5) | 3.44 (87.4) | 3.19 (81.0) | 1 | 10 |
| GPQC17-1/0 | 1 3/4 | — | #6 SOL – 1/0 STR (16 – 50) | 5.19 (131.8) | 4.00 (101.6) | 3.19 (81.0) | 1 | 10 |
| GPQC20-1/0 | 2 | — | #6 SOL – 1/0 STR (16 – 50) | 5.06 (128.5) | 4.00 (101.6) | 3.19 (81.0) | 1 | 10 |

A. System Overview

B1. Cable Ties

B2. Cable Accessories

B3. Stainless Steel Ties

C1. Wiring Duct

C2. Surface Raceway

C3. Abrasion Protection

C4. Cable Management

D1. Terminals

D2. Power Connectors

D3. Grounding Connectors

E1. Labeling Systems

E2. Labels

E3. Pre-Printed & Write-On Markers

E4. Permanent Identification

E5. Lockout/Tagout & Safety Solutions

F. Index