

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

NOTES, UNLESS OTHERWISE SPECIFIED:


PANDUIT TOOL NUMBER: CCT-320

THIS TOOLS' FEATURES INCLUDE:


 
- One hand operation due to an optimal force transmission ratio and a stepwise cutting up to 1-1/4" (32mm) diameter.
- Unlocking possibility in every position.
- All parts made of high tempered special steel.
- Blades and stressed parts are specially tempered or hardened.
- Tool has a burnished surface.
- Tool has ergonomically formed soft-handle grips.
- Tool is RoHS compliant and fully recyclable.
- Tool cuts both Copper and Aluminum solid cables from 1/4" (6mm) to 1" (25mm) and stranded cables up to 1-1/4" (32mm) in diameter.
- DO NOT USE THIS TOOL TO CUT STEEL OR ASCR CABLE.

APPROX. DIMENSIONS: 10" (254) x 3-3/4" (95) x 1" (25.4)

TOOL WEIGHT: 21oz., (600gr.)

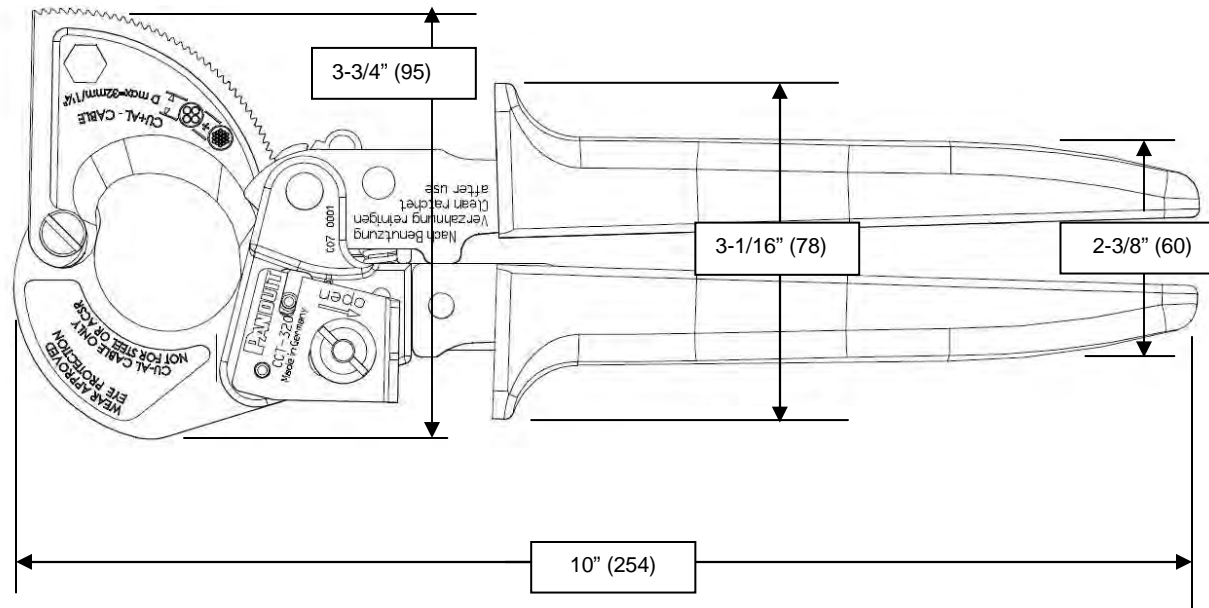

Find this drawing on TeamCenter

							CD * CCT-320 CABLE CUTTER						
							CUSTOMER DRAWING						
							ITEM REVISION NAME:						
							CG26095A01_01						
							UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE:			MATERIAL:			
							(.x) ± --- (.xxx) ± --- (.xx) ± --- ANGLES ± ---			-----			
							 THIRD ANGLE PROJECTION			DRAWING NUMBER: CG26095A01			
01	2-04-14	BLR	BJPU	ABJ	REDRAWN-NEW TEMPLATE; UPD BRANDING	4703	DRAWN BY: BJPU		DATE: 3-25-09	CHK ---	SCALE NONE	SHT 1 OF 1	SIZE A
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN							