




VZ-DSM-16 ADVANTAGES

- **16 output** server-based **Full HD** Video Wall Processor
- Delivers authentic details and stunning colors with **4K Ultra HD** content compatibility
- **Multi-display Media Server**, ideal for 4 x 4 video wall and digital menu board
- Up to 16 HDMI or DVI video outputs to extend visual landscape
- **Content management software**
- **Designed to operate 24/7/365 in mission-critical installations**
- Optional 4 VHDCI to HDMI cables and 4 VHDCI to DVI cables
- Max bit rate - 400Mbps (16 channel)

MODEL #	VZ-DSM-16
SPECIFICATIONS	
Processor	Intel® Xeon® E5 series processor
Storage	2 x 3.5" 500GB HDD
RAM	8GB DDR ECC (option: 16GB available)
Graphic	2 x VIA uH8 8-DISPLAY PCI-E graphics card
VIDEO	
Output	16 HDMI (DVI option)
RESOLUTION	
Per Channel / Display	Up to 1920 x 1080
INTERFACE	
HDMI (via VHDCI)	8 ea (DVI Option)
USB	2 ea
PS/2	2 ea
Serial Port	1 ea
VGA	1 ea
Network (RJ-45)	2 ea - 10/100/1000 Base-T
IPMI LAN Port	1 ea
GENERAL	
Power Supply	1 x 600W AC to DC PSU Power Input: 100 - 240V AC
Operating Temperature	41°F ~ 95°F / 5 °C ~ 35°C
Operating Humidity	10 % ~ 90 % (Non-condensing)
Dimensions (W x D x H)	16.8" x 19.8" x 5.2" / 427 x 503 x 132 mm
Net Weight	27.7 lbs / 6.35 Kg

DSM-16 CONNECTION DIAGRAM

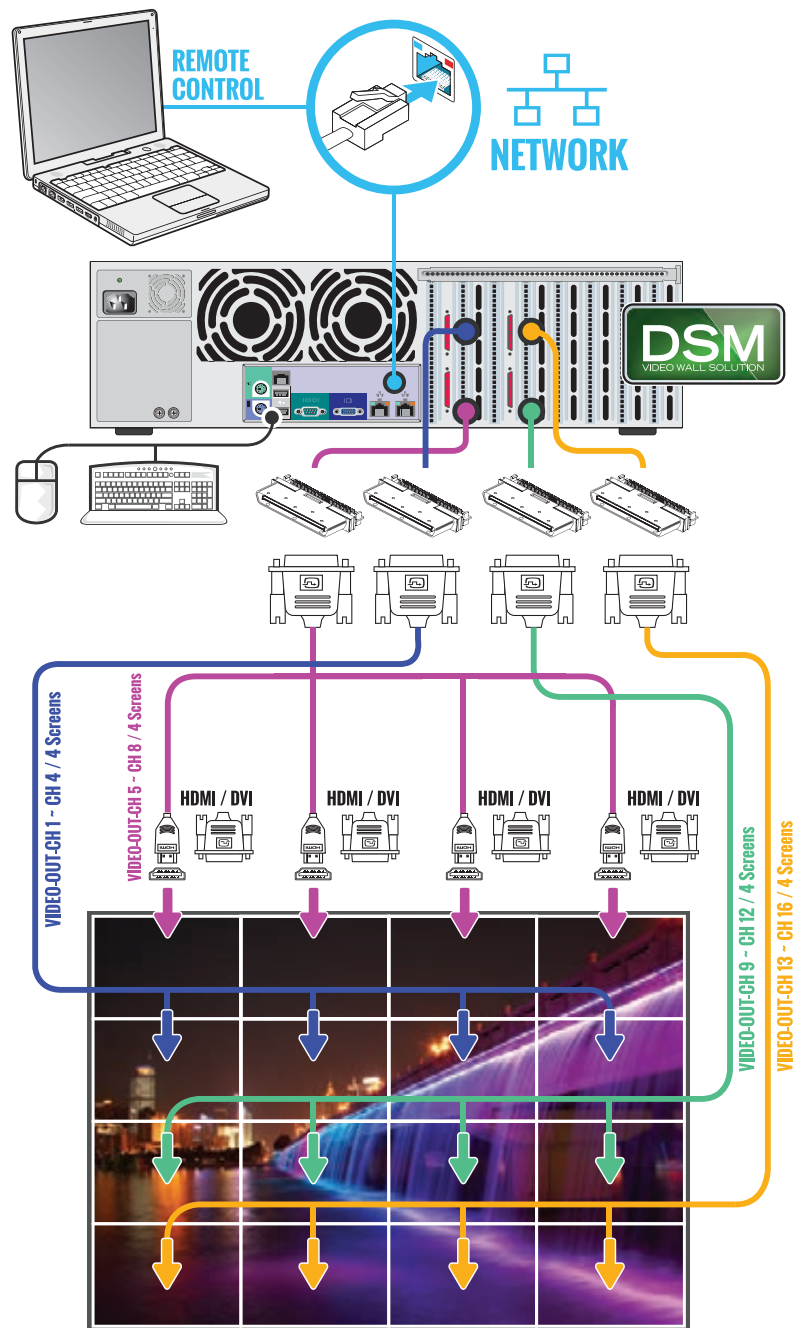

LED Video Wall Solution **UNL** Series **NL** Series

Contact ViewZ

- Address : 177 W. Orangethorpe Ave., Placentia, CA 92870
- Phone : (714) 996-1177, Fax : (714) 996-1138
- Sales : sales@viewzusa.com
- Specification subject to change without notice.