




HR Pro Series Micro VGA/QXGA HD15 plug to plug cables

Comprehensive's HR (High Resolution) Pro Series cables are "Comprehensive Classic" professional grade cables that provide excellent performance and value. That's why since 1974, they have been in use worldwide in stadiums, studios, stages, boardrooms, classrooms, schools, government installations and well, pretty much everywhere! HR Pro Series Cables cables are perfect for anyone looking for excellent quality at great price. Comprehensive HR Pro series Micro HD15 VGA cables are perfect for those tight spaces where a full size HD15 connector would be too large. These micro HD15 male to male cables are true high resolution construction with three individually 95% shielded coaxes for maximum signal transfer and high resolution video and graphics. The entire cable is then 100% shielded with a foil shield to eliminate EM and RF interference, even over long distances. Comprehensive goes the extra mile with machined pins which ensures the strength of each pin, to make sure they do not bend or break as imitation cables often do. Comprehensive HR Pro series cables provide thousands of connections and a lifetime of worry free use. UL and RoHS compliant. Lifetime Warranty.

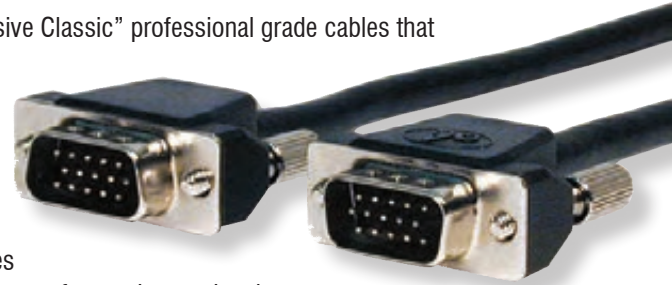

When it has to work, it has to be Comprehensive!

Features

- Micro HD15 Male to HD15 Male
- Designed to support high-resolution imaging up to QXGA 2048x1536
- 3 individually 95% tinned copper braid shielded coaxes
- 100% aluminum foil shield wrap provides extra coverage
- Micro molded design for easy connecting in tight spaces
- Molded strain relief for unsurpassed durability
- X-traflex jacket for easy installation
- UL and RoHS Compliant
- Lifetime Warranty

Specifications

Performance Grade: Good
 Connector Type 1: HD15 Male
 Connector Type 2: HD15 Male
 Resolution: 2048x1536
 Gauge: 32AWG
 Center Conductor: Tinned Copper
 Connector Finish: Nickel
 Shielding: Triple Shielded, Inner 95% Tinned Copper Wrap and 100% Aluminum Mylar, Outer 85% Tinned Copper Braid
 UL Rated: Yes

Ferrite Cores: No
 RoHS Compliant: Yes
 Jacket Type: Xtra-Flex PVC
 Jacket Color: Black
 Temperature Rating: 80 deg C
 Voltage: 30V
 Warranty: Lifetime

MVGA15P-P-3HR	3ft.
MVGA15P-P-6HR	6ft.
MVGA15P-P-10HR	10ft.
MVGA15P-P-15HR	15ft.
MVGA15P-P-25HR	25ft.

VGA CABLES



HR Pro Series Micro VGA/QXGA HD15 plug to plug cables
MVGA15-P-PxxHR

VGA CABLES

