




## WM110

Wall mount for indoor cameras

### Features:

- Good toughness and strength
- Beautiful design with wire outlet hole
- Coordination with small and nice appearance

### Dimension:

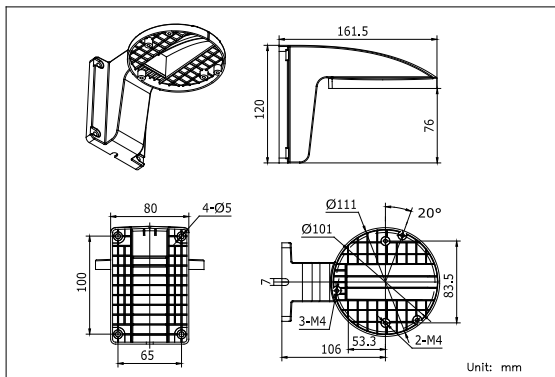

### Order model:

WM110 (was DS-1258ZJ)

### Parameters


Model	WM110
Parameters	Indoor wall mount
Color	Hik white
Feature	Suitable for mini dome or dome camera DS-2CD21x2-I
Material	ABS+PC
Dimension	111×120×161.5mm()
Weight	200g

### Notice:

- Pay attention to the application range when select bracket
- Pay attention to the color matching when select bracket
- The bracket should be installed on flat wall
- The wall must be capable of supporting more than 3 times the total load of the camera and the mount.
- The maximum load capacity of the mount is 2.0KG


### Installation steps:

- ① Select suitable wall to install the bracket and wire.

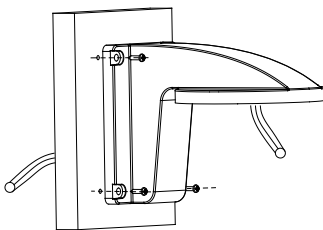


Notice: "A" stands for the lock screw


- ② Adjust the angle through the 3-axis adjustment structure.

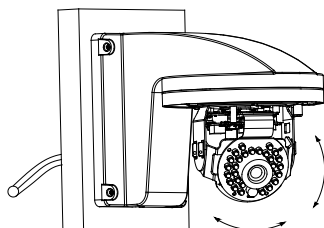


- ③ Loosen the tightening screw and take down the housing.

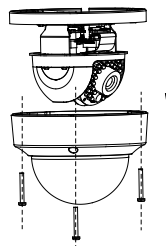


- ④ Install the housing and lock the screws.

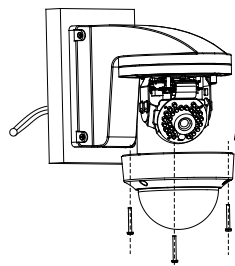

- ⑤ Install the dome core to the gang box, wire and lock the screw.

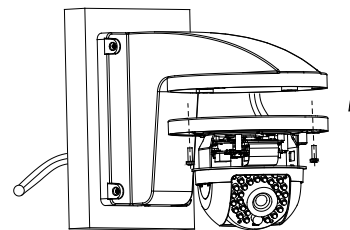

- ⑥ Install the housing and lock the screws.

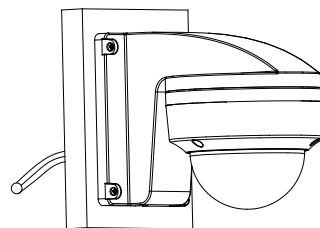

- ⑦ Finish the installation.

**Remark:** Appearance of Installation steps is for reference only