



N117 / 119
Single Console



Drawer Features & Display Benefits

- ▶ 1U 17" or 19" LCD console drawer
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 500mm (19.7") only
- ▶ Enhanced aesthetics with molded front handle and two point lock

Options

- S-Video + Composite (BNC) or Audio input
- HDMI or DVI-D (either one)
- 48V, 24V or 12VDC power

Specifications

• LCD Panel

Manufacturer :	AUO	AUO
Size (diagonal) :	17" TFT	19" TFT
Max resolution :	1280 x 1024	1280 x 1024
Brightness (cd/m2) :	250	250
Backlight :	CCFL	LED
Colors :	16.7 M	16.7 M
Contrast ratio (typ) :	1000 : 1	1000 : 1
Viewing angle (H/V) :	160° x 160°	170° x 160°
Active area (mm) :	338 x 270	376 x 301
MTBF (hrs) :	50,000	30,000
Signal input :	VGA	VGA

• Casing Color :

Black (RAL 9005)

• Weight (Single console)

Net :	12.3 kgs (27.1 lbs)	12.5 kgs (27.5 lbs)
Gross :	16.5 kgs (36 lbs)	17 kgs (37.4 lbs)

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Regulatory

Safety :	cUL, FCC & CE certified
Environmental	RoHS2 & REACH compliant

• Power

Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 48 Watt, Standby 5 Watt

• Dimensions (Single console)

Product :	441.6 x 500 x 44 mm / 17.4 x 19.7 x 1.73 inch
Packing :	590 x 768 x 140 mm / 23.2 x 30.2 x 5.5 inch

Console Cable


CE-6

6 feet Combo KVM cable (bundle)


- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

Keyboard

Ge G keyboard integrated with touchpad

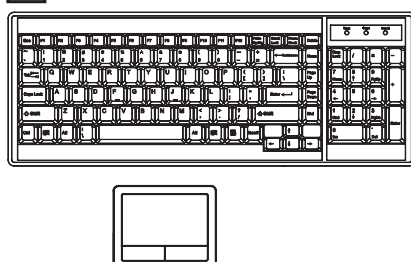

Gb G keyboard integrated with trackball

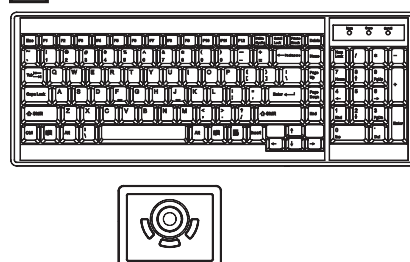

Supporting layouts

America					
	United States				
EMEA					
	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia	China	Japan	Korea	Arabia	Turkey


• Dimensions (with KVM)

Product : 441.6 x 620 x 44 mm / 17.4 x 24.4 x 1.73 inch

Packing : 590 x 768 x 140 mm / 23.2 x 30.2 x 5.5 inch

• Weight (Net / Gross)

N117 : 13.3 kgs (29.2 lbs) / 16.5 kgs (36.3 lbs)

N119 : 13.5 kgs (29.7 lbs) / 18.4 kgs (40.5 lbs)

• Casing Color : Black (RAL 9005)
www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MUKVM-KIT.pdf
 stands for 17" or 19" LCD size.

Matrix Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-	N11X - MUIP1613	N11X - MUIP3213
	1	1	2	-	N11X - MUIP1624	N11X - MUIP3224
	1	1	0	-	N11X - MU1602	N11X - MU3202
	1	2	0	-	N11X - MU1603	N11X - MU3203
	1	3	0	-	N11X - MU1604	N11X - MU3204

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-UKVM-KIT.pdf

Combo Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	N11X - UIP802	N11X - UIP1602	N11X - UIP3202
	1	1	0	N11X - U802	N11X - U1602	N11X - U3202
	1	0	0	N11X - U801	N11X - U1601	N11X - U3201

Cat6 KVM Dongle : DG-100S (VGA-USB) / DG-100 (VGA-PS/2) / DG-100SD (DVI-USB)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf

Matrix DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	N11X - MIP813	N11X - MIP1613	-
	1	1	2	N11X - MIP824	N11X - MIP1624	-
	1	1	0	N11X - M802	N11X - M1602	-
	1	2	0	N11X - M803	N11X - M1603	-
	1	3	0	N11X - M804	N11X - M1604	-

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf

Combo DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	N11X - IP802	N11X - IP1602	-
	1	1	0	N11X - 802	N11X - 1602	-
	1	0	0	N11X - S801	N11X - S1601	-

Combo DB-15 KVM Cable : CE-6 / 10 / 15 (6, 10 or 15 ft)

www.austin-hughes.com/support/usermanual/cyberview/UM-CV-DVIKVM-KIT.pdf

DVI-D KVM	Local	Remote	IP	12-port	-	-
	1	0	0	N11X - 1201D	-	-

DVI-D KVM Cable : CI-6 / 15 (6 or 15 ft)