


Circuit A :

W meter

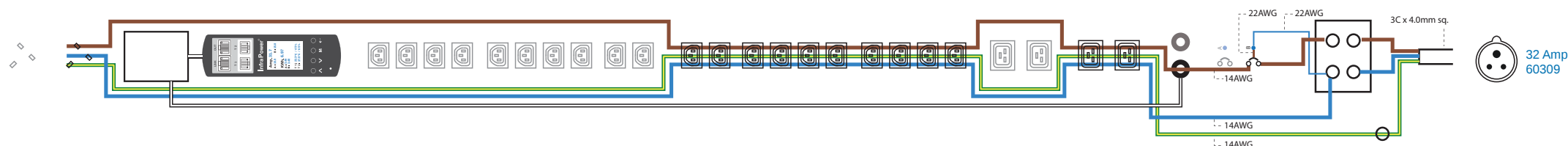

Circuit B :



The company reserves the right to modify product specifications without prior notice and assumes no responsibility for any error which may appear in this publication.

Copyright 2012 Austin Hughes Electronics Ltd. All rights reserved.

Description	: 2 outlets UK, 45 degree (left side mounting), 20 outlets IEC320 C13 & 4 outlets IEC320 C19
Cordset	: 3 meter 4mm sq H05V V-F cable with IEC60309 32A 2P + E plug
Receptacles	: 2 outlets UK BS1363 13A Rated, Angled 45 degree, 20 outlets IEC320 C13 10A Rated & 4 outlets IEC320 C19 16A Rated
Fuse	: 2 sets 16A Resettable Fuse
Meter	: RMS digital ammeter measuring input load current
Input Rating	: 32A / 250Vac
PDU Dimension	: 60 (W) x 50 (D) x 1500 (H) mm / Casing color :Black

Remarks	: For 32A Rating PDU, the models which have 26 socket outlets, < CIRCUIT A > The preceding of 1 UK, 10 C13 & 2 C19 socket outlets can only output 16A maximum. < CIRCUIT B > The back of 1 UK, 10 C13 & 2 C19 socket outlets can only output 16A maximum.
---------	---