
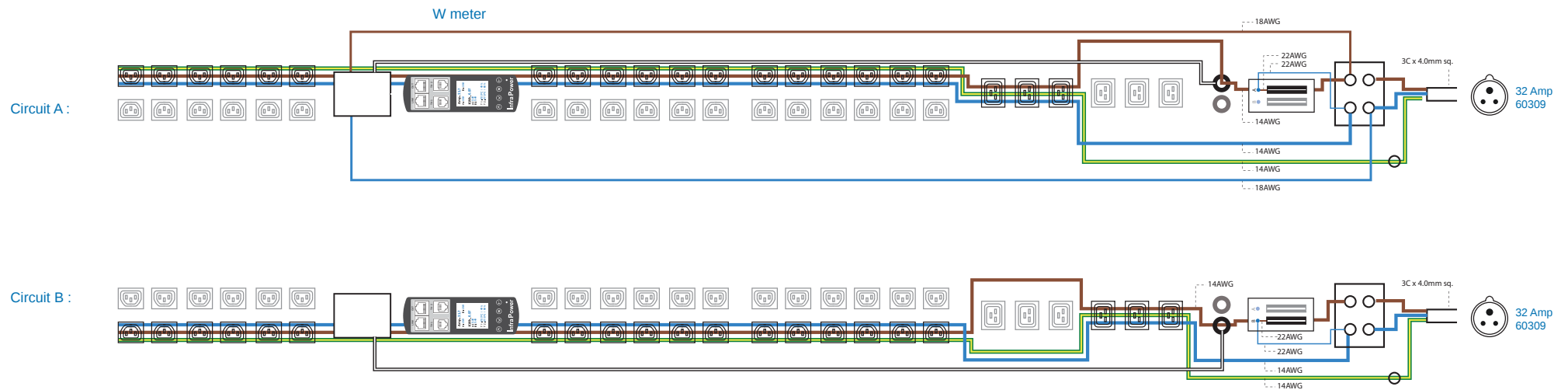


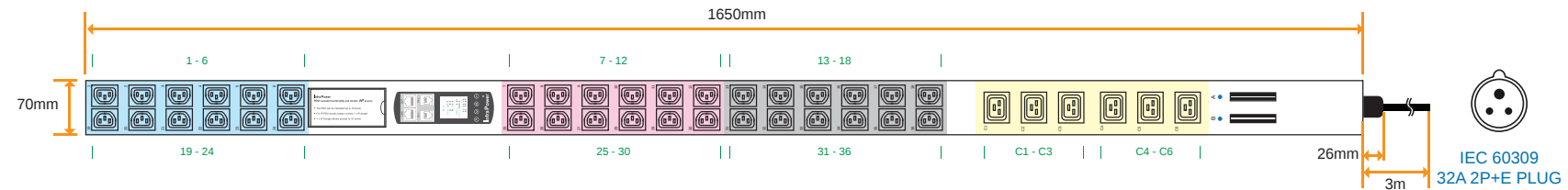

The company reserves the right to modify product specifications without prior notice and assumes no responsibility for any error which may appear in this publication.

Copyright 2013 Austin Hughes Electronics Ltd. All rights reserved.

Description	: 36 outlets IEC320 C13 & 6 outlets IEC320 C19
Cordset	: 3 meter 4mm sq H05V V-F cable with IEC60309 32A 2P + E plug
Receptacles	: 36 outlets IEC320 C13 10A Rated & 6 outlets IEC320 C19 16A Rated
Circuit Breaker	: 2 sets 16A Circuit Breaker
Meter	: RMS digital ammeter measuring input load current
Input Rating	: 32A / 250Vac
PDU Dimension	: 70 (W) x 60 (D) x 1650 (H) mm
Color	: Black
Remarks	: For 32A Rating PDU, the models which have 42 socket outlets, < CIRCUIT A > Socket #1-18 C13 & #C1-C3 C19 socket outlets can only output 16A maximum. < CIRCUIT B > Socket #19-36 C13 & #C4-C6 C19 socket outlets can only output 16A maximum.
Safety Regulatory	: FCC & CE certified
Environmental	: RoHS2 & REACH compliant by SGS