


Full HD 1080p Outdoor IR Bullet Cameras

ZIP2B 3.7mm fixed lens, dark grey housing

Features

- Real-time video up to 30fps
- PoE IEEE 802.3af
- Dual streaming
- Weather/vandal resistant
- IP66 compliant
- Only works with Speco's ZS, NS, and NSP NVRs
- 2 year warranty

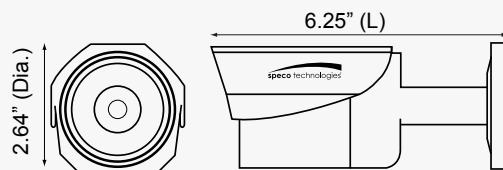

Camera Specifications

Image Sensor	1/2.8" 2.1MP CMOS
Maximum Resolution	1080p
Minimum Illumination	0 lux @F2.5 (IR on) 0.1 lux @F2.5 (IR off)
S/N Ratio	50dB
Shutter Speed	1/7 – 1/30,000 sec.
Exposure Control	Automatic
Motion Detection	Yes
Day/Night	IR-cut filter
Number of IR LEDs	24
IR Range	50' (depending on scene reflection)
IR Wavelength	850nm
White Balance	Automatic
DNR	2D/3D Automatic

Video Specifications

Supported Resolutions	1920x1080@30fps / 1280x720@30fps
Compression	H.264 (Main / Baseline Profile)
Bitrate Control	CBR
Multiple Streaming	2 simultaneous profiles

Network Specifications

Interface	10/100 Base-T
Security	User ID & password protection
User Access	4 concurrent users
Web Browser Support	Internet Explorer 8 and up

Operating & Unit Specifications

Power Supply	802.3af PoE or 12VDC
Power Consumption	12VDC, 360mA (IR on)
Operating Temperature	-4° F – 122° F
Unit Weight	15.36 oz.
Unit Dimensions	2.64" (Dia.) x 6.25" (L)
Certifications	FCC, RoHS
Included in Package	Unit, CD (manual, software), mounting plate L wrench, mounting screws

Optional Accessory



PSW5
12VDC
Power Supply

Speco Technologies is constantly developing and improving products.
We reserve the right to modify product design and specifications without notice
and without incurring any obligation. Spec Rev. 1/10/14