

960H Color Indoor Dome Camera

VL644H

3.6mm fixed lens, black housing


VL644HW

3.6mm fixed lens, white housing

Features

- 750 TV lines of resolution
- Easy installation & adjustment
- Compact & lightweight 3 axis design
- Manual 360° rotation & pan/tilt mechanism
- Low power consumption - max. 90mA
- 12VDC power supply required (power supply not included)
- 5 year warranty

960

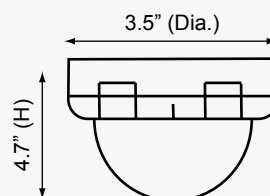

Specifications

Image Sensor	1/3" High Resolution 960H CCD Sensor
Resolution.....	750 TV lines of resolution
Minimum Illumination.....	0.001 lux @ F=1.2
Effective Pixels	1028 (H) x 508 (V)
Electronic Shutter	Auto (1/60 sec. - 1/100,000 sec.)
S/N Ratio	52dB
Backlight Compensation.....	Auto
Synchronization	Internal
Gamma	0.45 typ.
Video Signal Output.....	1.0Vp-p / 75 ohms
Operating Temperature/	
Humidity.....	14° F – 122° F / less than 80% RH
Storage Temperature.....	-4° F – 140° F
Power Consumption	90mA
Power Supply	12VDC (power supply not included)
Dimensions.....	4.7" (H) x 3.5" (Dia.)
Weight	10.5 oz.

Speco Technologies is constantly developing and improving products.
We reserve the right to modify product design and specifications without notice
and without incurring any obligation.
Spec Rev. 12/16/13

Optional Accessory



PSW5
12VDC
Power Supply