

Color LED Flat-Panel Monitor

M17VLED 17" LED monitor



M19VLED 19" LED monitor

Features

- Flat-panel LED - backlit LCD
- VGA (D-Sub 15 pins) and BNC video inputs
- 1280 x 1024 max. resolution
- Built-in speakers
- Convenient front controls for screen programming
- Input signal detection provides easy connection
- 290cd/m2 brightness
- 4:3 display ratio
- 800:1 contrast ratio
- Displays up to 16.7 million colors
- Regulated 12VDC 5.0 amp (UL & CSA listed power supply included)
- VESA compatible
- 1 year warranty



Specifications	M17VLED	M19VLED
Composite Output	BNC 1	
Composite Input	BNC 1	
Single Connector	VGA x 1, RCA x 2, PC Audio x 1	
Speaker	1W+1W	
Display Mode	VGA / BNC / PC / S-Video	
AC Power	AC 100 - 240V 50/60Hz	
Operating Temperature	14° F – 122° F	
Storage Temperature	-4° F – 140° F	
Power Consumption	25W	
OSD Control	VGA, Audio, PIP, System	
OSD Languages	English	
Auto Adjustment	Yes	
De-interlace	Yes	
Wall Mount	Optional	
Accessories	Adaptor, Power Cord, Manual, VGA cable, PC Audio Cable	
Safety	FCC, CE, RoHS	
Tilt	10° – 15°	
Humidity	20% – 85%	
Monitor Scan	Microprocessor controlled	
Pixel Pitch	0.264mm	0.294mm
Pixel Format	1280 x 1024	
Response Time	5ms	
Color Depth	16.7 million colors	
Viewing Angle	Left 80° / Right 80° / Up 80° / Down	Left 85° / Right 85° / Up 85° / Down
Display Area	13.31" (H) x 10.64" (V)	14.82" (H) x 11.85" (W)
Dimensions	14.64" (W) x 13.89" (H)	16.53" (W) x 15.74" (H)
Weight	7 lbs.	8 lbs.

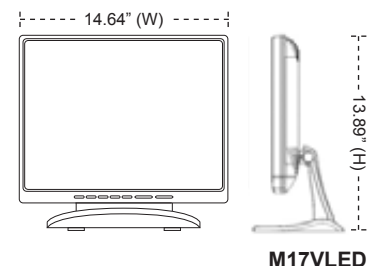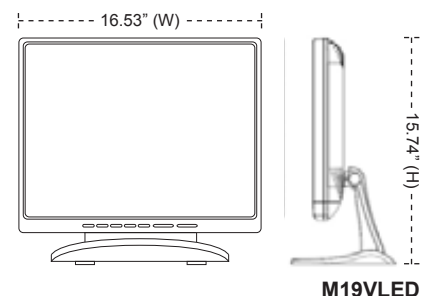

Optional Accessory



LCDVLW2
10" Extension Arm

Speco Technologies is constantly developing and improving products.
We reserve the right to modify product design and specifications without notice
and without incurring any obligation. Spec Rev. 2/6/14