


Intensifier K™ 1000 TVL Indoor/Outdoor Vandal Resistant Bullet with True WDR

HTINT70K 2.8-12mm auto-iris varifocal lens, dark grey housing

Features

- 1/3" 1.3 MP Sony Sensor
- 1000 TV lines the highest resolution in analog
- True WDR functionality
- Superior low-light performance
- Amplify existing light with no distance limitation
- Heater circuitry eliminates fog or condensation under any weather condition
- Presets include Indoor, Outdoor, Low Light, Hallway, Lobby (WDR), Elevator
- 12VDC & 24VAC dual voltage operation
- Relay output for motion detection
- 3-axis wall and ceiling mount
- Vandal / tamper resistant operation
- IP67 compliant
- 5 year warranty

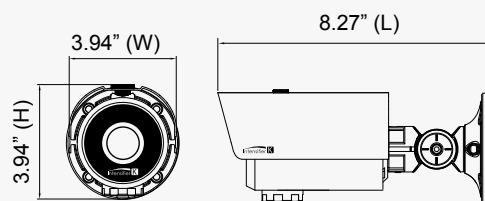

Specifications

Image Sensor	1/3" 1.3MP Sony Sensor
Resolution.....	1000 TV lines
Minimum Illumination.....	0.0001 lux
Effective Pixels	1305 (H) x 1049 (V)
Total Pixels	1312 (H) x 1069 (V)
TV System.....	NTSC
Scanning System.....	Progressive
S/N Ratio	More than 50dB
Frame Rate.....	Max 50P/60P
Video Output	1.0Vp-p / 75 ohms
Lens.....	DC / Manual
Electronic Shutter Speed.....	Auto / Manual (1/60 sec. - 1/60,000 sec.) / Flicker
WDR.....	On (Low / Middle / High) / Off
Digital WDR.....	On (Low / Middle / High) / Off
Day/Night.....	Color / BW / Auto / Ext
White Balance	Auto / Auto Ext / AWC – SET / Manual
Brightness.....	0 - 20 (level adjustable)

AGC.....	0 - 20 (level adjustable)
Sense-Up.....	(x2 – x32)
Motion Tracking.....	On / Off
Motion Detection.....	On / Off (4 zones)
Privacy.....	On / Off (16 zones)
Mirror / V-Flip.....	On / Off
Sharpness	0 - 15 (level adjustable)
Lens Shading Compensation	On / Off
3DNR.....	Off / Low / Middle / High
Defog.....	On (Auto / Manual) / Off
DIS.....	On / Off
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Power Consumption	12VDC, 590mA / 24VAC, 230mA
Operating Temperature.....	-4° F – 140° F
Dimensions.....	3.94" (W) x 3.94" (H) x 8.27" (L)
Weight	3.09 lbs.

Optional Accessories



INTJBS
Square
Junction Box



INTCM
Corner/Pole
Adaptor



CVCJBB
Bullet Camera
Junction Box



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply



Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 2/4/14