


960H Indoor/Outdoor IR Bullet Camera with 10x Optical Motorized Zoom

HTB10XH 3.8-38mm auto iris varifocal lens (10x optical zoom)

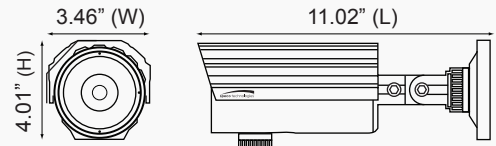

Features

- 1/3" Sony ExView™ CCD
- 700 TV lines of resolution
- 35 IR LEDs
- Highest resolution: vivid sharp picture in complete darkness
- Motorized zoom lens control via RS485
- 3DNR (digital noise reduction)
- DWDR (digital wide dynamic range)
- Smart digital zoom
- Full OSD operation
- Digital image stabilizer
- IP67 compliant
- 12VDC / 24VAC dual voltage operation
- 5 year warranty

Specifications

Image Sensor	1/3" Sony ExView™ CCD
Resolution.....	700 TV lines
Minimum Illumination.....	0 lux
Effective Pixels	976 (H) x 494 (V)
Total Pixels	1028 (H) x 508 (V)
TV System.....	NTSC
Scanning System.....	2:1 interlace
Number of IR LEDs	35
IR Range	98 ft. (depending on scene reflection)
IR LED Wavelength	850nm
S/N Ratio	52dB
Video Output.....	1.0Vp-p / 75 ohms
Backlight Compensation.....	On / Off
Day/Night.....	Auto / Color / BW / Ext
AGC.....	High / Middle / Low
Sense-Up.....	Auto / Off (x2 – x256)
White Balance	ATW / AWB / AWC – Set / Manual (1,800°K – 10,500°K)

Mirror	H-Rev / V-Rev / Rotate / PIP
Digital Zoom	x12
Defect Compensation.....	Auto (256 points)
3DNR.....	On / Off / Smart
DIS.....	On / Off
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Power Consumption	12VDC, 700mA / 24VAC, 350mA
Storage Temperature/ Humidity.....	-4° F – 140° F / 20% – 95% RH
Operating Temperature/ Humidity.....	-4° F – 140° F / 20% – 80% RH
Dimensions.....	3.46" (W) x 4.01" (H) x 11.02" (L)
Weight	3 lbs.

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 1/16/14



Optional Accessories



INTCM
Corner/Pole
Adaptor



INTJBS
Square
Junction Box



CVCJBB
Round
Junction Box



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply