


## 960H Weather Resistant IR Bullet Camera

**CVC617H** 4.3mm fixed lens, dark grey housing

### Features

- 1/3" 960H color CCD
- 700 TV lines of resolution
- IR Range: 65' (depending on scene reflection)
- Weather resistant operation
- IP66 compliant
- 12VDC operation
- Mounting bracket included
- 5 year warranty

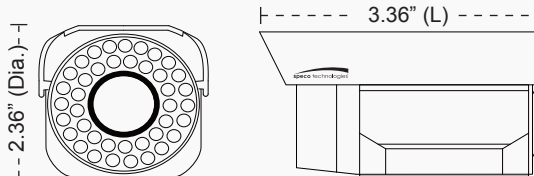

### Specifications

Image Sensor	1/3" 960H color CCD
Resolution	700 TV lines
Minimum Illumination	0.00 lux (IR LED on)
Effective Pixels	976 (H) x 494 (V)
Total Pixels	1020 (H) x 508 (V)
Number of IR LEDs	24
IR Range	65' (depending on scene reflection)
Scanning System	2:1 interlaced
Synchronization	Internal
S/N Ratio	48dB
Video Output	CVBS: 1.0Vp-p, 75 ohms
Electronic Shutter Speed	1/60 sec. – 1/100,000 sec.
Backlight Compensation	Automatic
AGC	Automatic
Power Consumption	120mA (IR LED off), 350mA (IR LED on)
Power Supply	12VDC (power supply not included)
Operating Temperature	14° F – 120° F
Dimensions	2.36" (Dia.) x 3.36" (L)
Weight	12.8 oz.
Included in Package	Mounting bracket with screws

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 1/20/14



### Optional Accessory



**PSW5**  
12VDC  
Power Supply