


**960H 700TVL IR Bullet Camera**  
**Weather Resistant**

**Model No. : CVC617H**



200 New Highway, Amityville, NY 11701

800-645-5516 / [www.specotech.com](http://www.specotech.com)

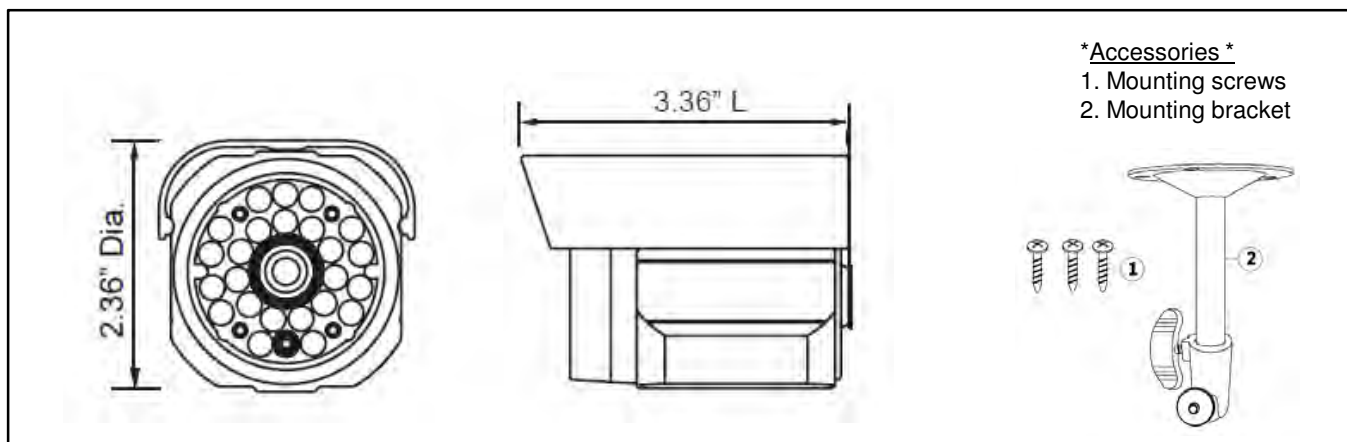

**GENERAL FEATURE**

- 700 lines of color resolution
- 24 IR LEDs / 65' IR range
- Weather resistant operation
- Includes mounting bracket
- IP66 compliant

**INSTALLATION**

- 1) Connect Video & Power Line (12V DC Regulated Power)
- 2) Set the position where you want to connect the camera
- 3) Loosen the locking screws and adjust the camera angle
- 4) Combine each camera part and lock & tighten each locking screw

**SPECIFICATIONS**

MODEL NO.	CVC617H
Image Sensor	1/3" 960H COLOR CCD
Lens	Fixed Lens
Number of Pixels	976(H) x 494(V)
Horizontal Resolution	700TVL
Minimum Illumination	0.00Lux (IR LEDs on)
Electronic Shutter Speed	1/60~1 / 100,000sec
S/N Ratio	More than 48dB
Scanning System	2 : 1 Interlaced
Sync. System	Internal
Video Output	1.0Vp-p 75ohm composite
Power Consumption	IR-Off (120mA), IR-On (350mA) at DC12V
Operating Temperature	14°F – 120°F
Weight	12oz.