
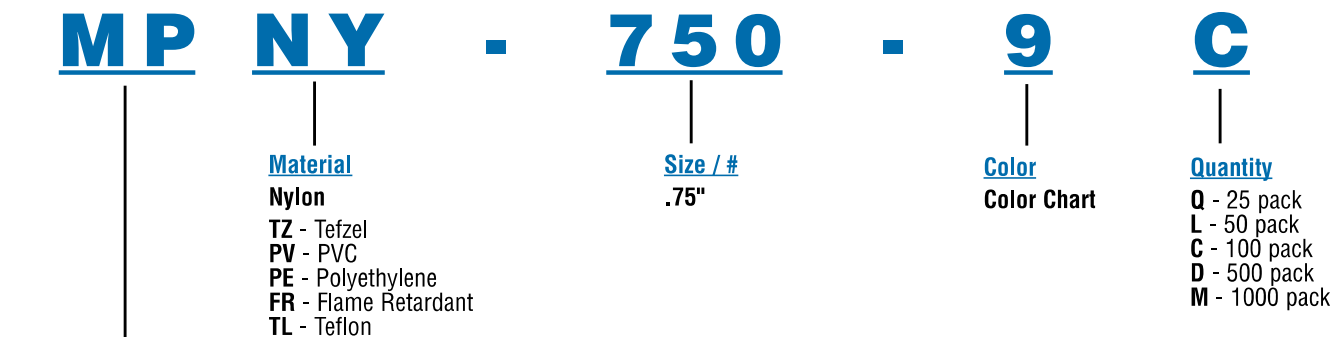


Catamount®

Cable Ties


Part Number Construction

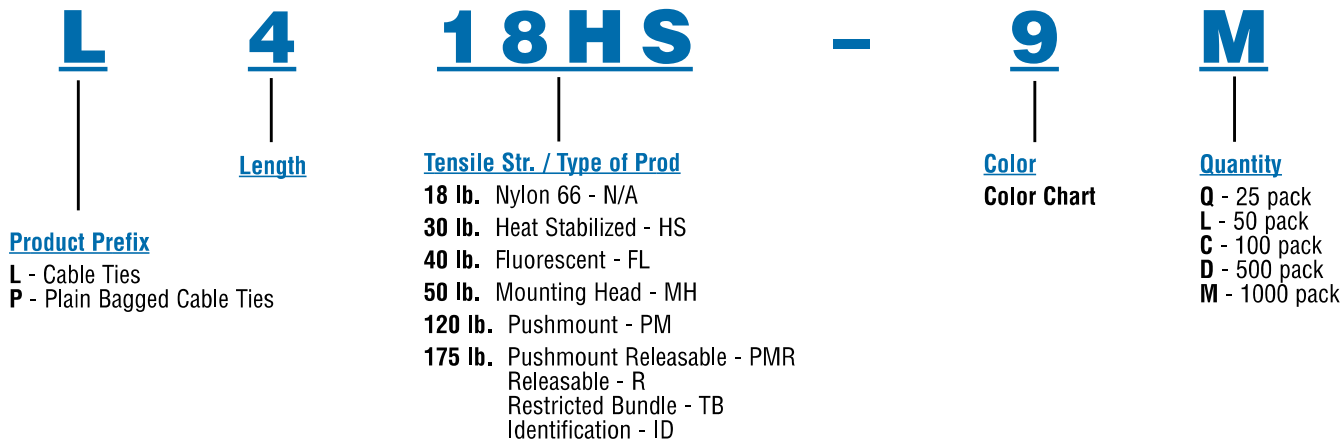

Color Table


0 – Black (Outdoor)	8 – Gray
1 – Brown	9 – Natural
2 – Red	11 – Fluorescent Pink
3 – Orange	16 – Fluorescent Orange
4 – Yellow	17 – Fluorescent Yellow
5 – Green	18 – Fluorescent Green
6 – Blue	20 – Fluorescent Blue
7 – Purple	

Cable Tie Accessories

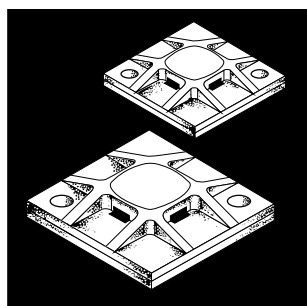

Mounting Pads

- 3/4" and 1" mounts for use with 18# through 50# tensile cable ties.

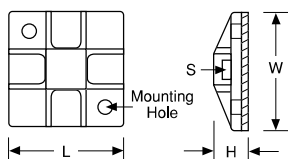

- Supplied "two-up" on rubber based (synthetic polymer) closed cell foam adhesive, "single-cut" for acrylic Based adhesive or with no adhesive for #6 screw mount applications.
- Available in 6/6 Natural Nylon and heat stabilized Black Nylon.
- UL Flammability 94 V-2 (clip).



3/4" x 3/4" Mount

Cat. No. Std.	Cat. No. Bulk	Material	Mount Method	Height		Length		Width		Slot Height		Slot Width		Std. Pkg.	Qty.
				Inch	(mm)	Inch	(mm)	Inch	(mm)	LB	(kg)	Inch	(mm)		
MPNY-750-0-C	MPNY-750-0-D	Black Nylon	Synthetic Polymer	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
MPNY-750-9-C	MPNY-750-9-D	Natural Nylon	Synthetic Polymer	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
MPNY-750A-0-C	MPNY-750A-0-D	Black Nylon	Acrylic Adhesive	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
MPNY-750A-9-C	MPNY-750A-9-D	Natural Nylon	Acrylic Adhesive	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
MPNY-750S-0-C	MPNY-750S-0-D	Black Nylon	#6 Screw	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
MPNY-750S-9-C	MPNY-750S-9-D	Natural Nylon	#6 Screw	.205	(5.21)	.750	(19.04)	.750	(19.04)	.050	(1.27)	.140	(3.18)	100	500
Tolerance ±				.010		.015		.010		.010		.010			

For use with 18-40 lb. Cable Ties.



1" x 1" Mount

Cat. No. Std.	Material	Mount Method	H Height		L Length		W Width		S Slot Height		S Slot Width		Std. Pkg.
			Inch	(mm)	Inch	(mm)	Inch	(mm)	LB	(kg)	Inch	(mm)	
MPNY-1000-0-C	Black Nylon	Synthetic Polymer	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
MPNY-1000-9-C	Natural Nylon	Synthetic Polymer	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
MPNY-1000A-0-C	Black Nylon	Acrylic Adhesive	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
MPNY-1000A-9-C	Natural Nylon	Acrylic Adhesive	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
MPNY-1000S-0-C	Black Nylon	#6 Screw	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
MPNY-1000S-9-C	Natural Nylon	#6 Screw	.215	(5.46)	1.000	(25.40)	1.000	(25.40)	.070	(1.78)	.203	(5.16)	100
Tolerance ±			.010		.015				.010		.010		

For use with 18-50 lb. Cable Ties.

- **Mounting Surface should be cleaned with alcohol based (IPA) cleaner before application.**
- **Rubber Based adhesive provides instant adhesion. Acrylic Based may be repositioned initially. Allow 24-72 hours set-up for maximum performance with Acrylic Based adhesives.**