
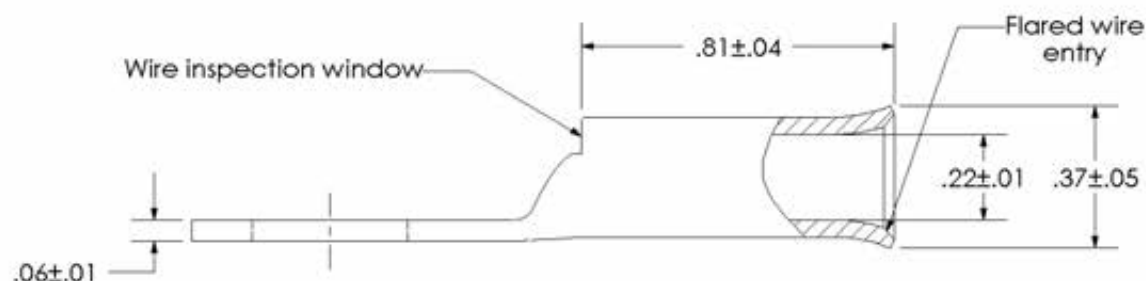


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

|                                                |                                                                                                                                                |
|------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------|
| Material                                       | High Conductivity Seamless Copper Tube                                                                                                         |
| Plating                                        | Electro-Tin                                                                                                                                    |
| Wire Size & Type                               | Stranded Copper Flex Cable; 6 AWG (61/24) Diesel Locomotive, 6 AWG FLEX K,M Class K & Class M                                                  |
| Wire Strip Length                              | 7/8 in.                                                                                                                                        |
| Stud Size                                      | 3/8 in.                                                                                                                                        |
| UL Listed Wire Connector                       | Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. |
| UL Temperature Rating                          | 90° C                                                                                                                                          |
| C.S.A Certified Wire Connector                 | Yes                                                                                                                                            |
| Panduit Color Code on Barrel                   | BLUE                                                                                                                                           |
| Panduit Die Index No. on Barrel                | P24                                                                                                                                            |
| Alternate Industry Die Index No. ( ) on Barrel | (7)                                                                                                                                            |

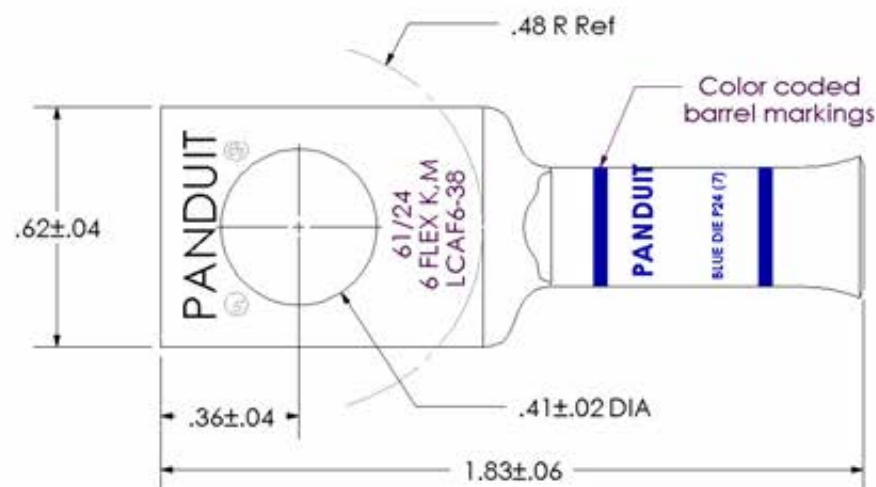

|     |      |     |     |             |       |
|-----|------|-----|-----|-------------|-------|
| 00  | 9/02 | SAB | DRL | RELEASED    | 10321 |
| REV | DATE | BY  | CHK | DESCRIPTION | ECN   |

|                                                    |                                        |
|----------------------------------------------------|----------------------------------------|
| <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b>         |                                        |
| LCAF6-38-L<br>Copper Lug - One-Hole, Flared Barrel |                                        |
| SCALE<br>N/A                                       | DRAWING NO / CAD FILE<br>LCAF6-38-CUST |