

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


|                                                      |                                                                                                                                                            |
|------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Material                                             | High Conductivity<br>Seamless Copper Tube                                                                                                                  |
| Plating                                              | Electro-Tin                                                                                                                                                |
| Wire Size                                            | 6 AWG                                                                                                                                                      |
| Wire Type                                            | Stranded Copper; Class B:<br>Compact, Compressed or<br>Concentric, Class C: Concentric                                                                     |
| Wire Strip Length                                    | 1-1/4 in.                                                                                                                                                  |
| Stud Size                                            | 1/4 in.                                                                                                                                                    |
| UL Listed Wire<br>Connector                          | Yes, for applications up to 35kv.<br>Consult cable manufacturer for<br>voltage stress relief instructions<br>with applications greater than<br>2000 volts. |
| UL Temperature<br>Rating                             | 90 ° C                                                                                                                                                     |
| C.S.A Certified<br>Wire Connector                    | Yes                                                                                                                                                        |
| Panduit Color Code<br>on Barrel                      | BLUE                                                                                                                                                       |
| Panduit Die Index No.<br>on Barrel                   | P24                                                                                                                                                        |
| Alternate Industry<br>Die Index No. ( )<br>on Barrel | (7)                                                                                                                                                        |



CERTIFIED



LISTED  
Wire Connector

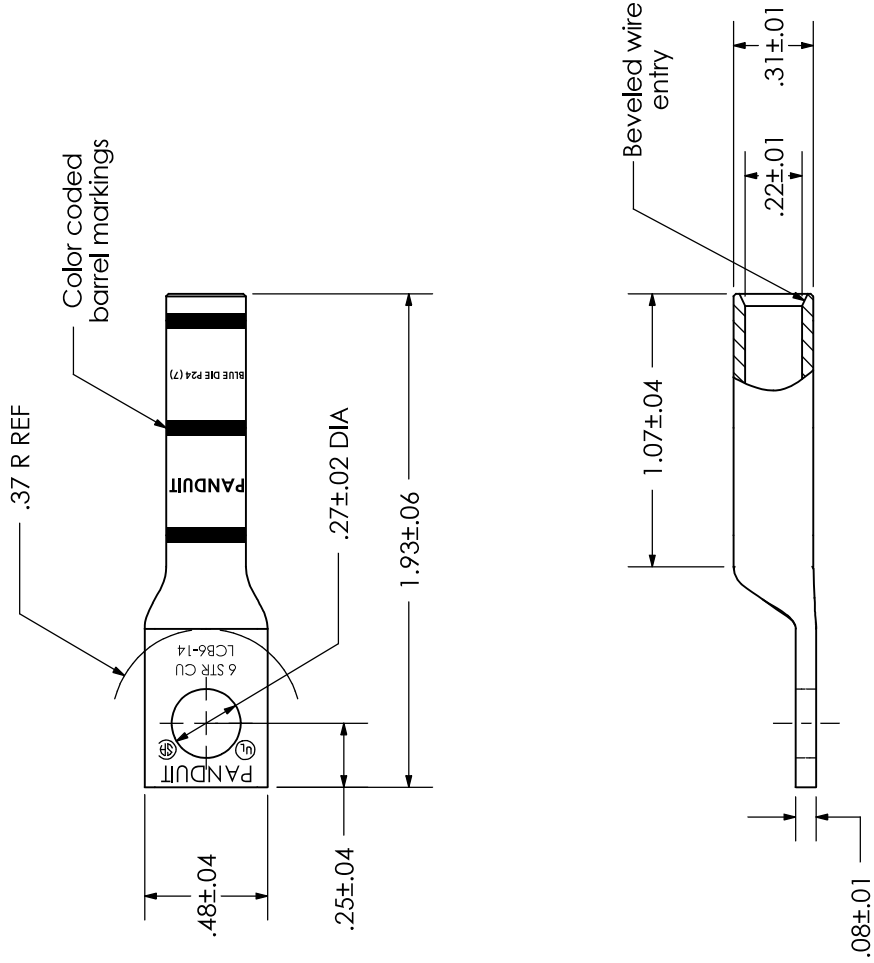

|                                            |       |              |     |
|--------------------------------------------|-------|--------------|-----|
| <b>PANDUIT</b> CORP. TINLEY PARK, ILLINOIS |       |              |     |
| LCB6-14-L                                  |       |              |     |
| Copper Lug - One-Hole, Long Barrel         |       |              |     |
| REV                                        | DATE  | BY           | CHK |
| 01                                         | 11/08 | DRL          | DRL |
| REMOVED NAVY NO.                           |       |              |     |
| DESCRIPTION                                |       |              |     |
| ECN                                        |       | SCALE        | N/A |
| DRAWING NO / CAD FILE                      |       | LCB6-14-CUST |     |