

Product Information Sheet

CABINET SERVICE PARTS FOR MEGAFRAME AND SLIMFRAME CABINETS

Chatsworth Products, Inc. (CPI) now offers a complete line of service parts for M-Series MegaFrame and C-Series SlimFrame Cabinets. Order doors, side panels or top panels to replace items that have been damaged, to add to frame-only configurations or to meet the changing environment of your data center.

Replacement doors are available in several styles including solid or vented plexiglass and solid or high-flow perforated metal. The high-flow perforated metal door has a 63% open area for maximum ventilation. Doors are easy to remove and can be mounted to open from the left or right. Keyed locks are pre-installed and include two keys.

Side panels for MegaFrame and SlimFrame Cabinets are offered in two styles: the easy-to-remove locking side panel and the bolt-on side panel. The easy-to-remove side panel allows quick access to equipment in a fully loaded cabinet. Side panels ship with two keys per panel.


Top panels are vented with edge-protected cable pass through ports. (A solid top panel is available for the MegaFrame Cabinet.) Optional fan kits can be mounted to top panels to provide additional ventilation.

Most service parts are available in gray, white or black. MegaFrame and SlimFrame service parts are constructed of high-strength aluminum. Door frames are silver anodized aluminum.


When ordering a service part, ensure it matches the cabinet's dimensions. Call Technical Support for additional assistance or to order parts not listed.

- Wide selection of service parts for replacing damaged parts, adding to frame-only configurations or upgrading to meet changing needs.
- Perforated metal doors have 63% open area for greater ventilation.
- Easy-to-remove locking side panels
- Top panels are vented and accommodate optional fan kits for maximum ventilation.

For more information, please contact your authorized CPI Distributor or CPI Customer Service Representative, or go to www.chatsworth.com.

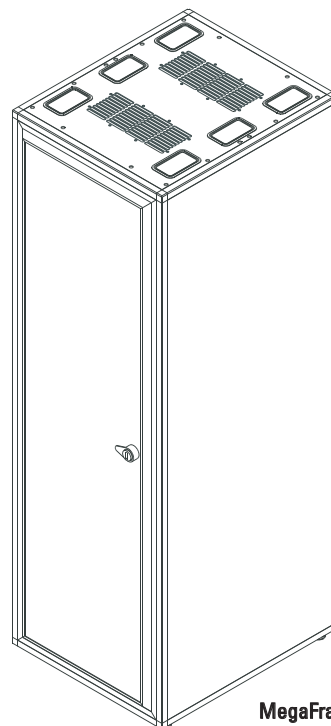

MegaFrame Cabinet

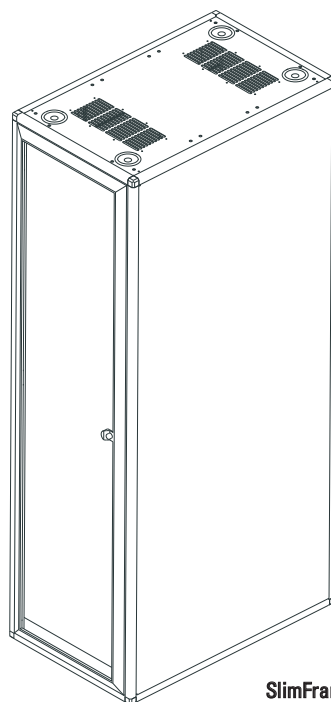

SlimFrame Cabinet

800-834-4969 in U.S. & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS, INC.

Product Information Sheet

CABINET SERVICE PARTS FOR MEGAFRAME AND SLIMFRAME CABINETS

MegaFrame & SlimFrame Cabinets

Example Part Number: 30370-710

Traditional Single Door	
14032	MegaFrame High-Flow Perforated Metal
14030	MegaFrame Solid Plexiglass
14031	MegaFrame Solid Metal
14033	MegaFrame Vented Plexiglass*
12882	SlimFrame High-Flow Perforated Metal
12885	SlimFrame Solid Plexiglass
12886	SlimFrame Solid Metal
12887	SlimFrame Vented Plexiglass*
Double Door	
30370	MegaFrame Solid Plexiglass
30371	MegaFrame Solid Metal
30372	MegaFrame High-Flow Perforated Metal
30373	MegaFrame Vented Plexiglass*
30380	SlimFrame Solid Plexiglass
30381	SlimFrame Solid Metal
30382	SlimFrame High-Flow Perforated Metal
30383	SlimFrame Vented Plexiglass*

Color	
0	No Color (Solid Plexiglass Doors Only)
1	Gray
2	White
7	Black

Cabinet Width	
1	19" Rack Mount
2	23" Rack Mount

Cabinet Height	
0	84" (2130 mm) Overall
1	78" (1980 mm) Overall
2	72" (1830 mm) Overall
5	48" (1220 mm) Overall**
9	28" (710 mm) Overall**

XXXXX - X X X

*Vented plexiglass available in black only.

**MegaFrame only; no double doors

Top Panel	
10585	MegaFrame Vented w/Cable Ports
12888	MegaFrame Solid w/o Cable Ports
12535	SlimFrame Vented w/Cable Ports
12895	Seismic MegaFrame Vented w/Cable Ports

Color	
1	Gray
2	White
7	Black

Cabinet Width	
1	19" Rack Mount
2	23" Rack Mount

Cabinet Depth	
6	22.0" (560 mm) Usable, 24.0" (610 mm) Outside*
2	24.0" (610 mm) Usable, 26.1" (663 mm) Outside**
3	30.0" (760 mm) Usable, 32.1" (815 mm) Outside
5	36.0" (910 mm) Usable, 38.1" (968 mm) Outside
4	39.0" (990 mm) Usable, 41.1" (1044 mm) Outside**

1XXXX - X X X

*SlimFrame only.

**MegaFrame only

Side Panel	
14029	Bolt-On
12884	Easy-to-Remove

Color	
1	Gray
2	White
7	Black

Cabinet Depth	
6	22.0" (560 mm) Usable, 24.0" (610 mm) Outside**
2	24.0" (610 mm) Usable, 26.1" (663 mm) Outside**
3	30.0" (760 mm) Usable, 32.1" (815 mm) Outside
5	36.0" (910 mm) Usable, 38.1" (968 mm) Outside
4	39.0" (990 mm) Usable, 41.1" (1044 mm) Outside**

Cabinet Height	
0	84" (2130 mm) Overall
1	78" (1980 mm) Overall
2	72" (1830 mm) Overall
5	48" (1220 mm) Overall**
9	28" (710 mm) Overall**

1XXXX - X X X

*SlimFrame only.

**MegaFrame only

800-834-4969 in U.S. & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS, INC.

©2009 Chatsworth Products, Inc. All rights reserved. CPI, CPI Passive Cooling, Saf-T-Grip, Seismic Frame, SlimFrame and MegaFrame are federally registered trademarks of Chatsworth Products, Inc. Cube-iT Plus, Evolution, OnTrac, QuadraRack, Simply Efficient and TeraFrame are trademarks of Chatsworth Products, Inc. All other trademarks belong to their respective companies.
MKT-60020-198 Rev.5 05/09