



**RKP117 / 119**  
Single Console



### Drawer Features & Display Benefits

- ▶ 1U 17" or 19" LCD console drawer
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 460mm and 500mm respectively
- ▶ New enhanced aesthetics with molded front handle
- ▶ Front USB port for device access ( USB Hub KVM only )
- ▶ 2 post rack mounting available

### Options

- S-Video + Composite ( BNC ) or Audio input
- HDMI or DVI-D ( either one )
- 48V, 24V or 12VDC power

### Specifications

#### • LCD Panel

|                        |             |             |
|------------------------|-------------|-------------|
| Manufacturer :         | <b>AUO</b>  | <b>AUO</b>  |
| Size (diagonal) :      | 17" TFT     | 19" TFT     |
| Max resolution :       | 1280 x 1024 | 1280 x 1024 |
| Brightness (cd/m2) :   | 250         | 250         |
| Backlight :            | CCFL        | LED         |
| Colors :               | 16.7 M      | 16.7 M      |
| Contrast ratio (typ) : | 1000 : 1    | 1000 : 1    |
| Viewing angle (H/V) :  | 160° x 160° | 170° x 160° |
| Active area (mm) :     | 338 x 270   | 376 x 301   |
| MTBF (hrs) :           | 50,000      | 30,000      |
| Signal input :         | VGA         | VGA         |

#### • Casing Color :

Black ( RAL 9005 )

#### • Weight ( Single console )

|         |                          |                          |
|---------|--------------------------|--------------------------|
| Net :   | 12 kgs<br>( 26 lbs )     | 12.7 kgs<br>( 27.9 lbs ) |
| Gross : | 16.6 kgs<br>( 36.5 lbs ) | 17.3 kgs<br>( 38.1 lbs ) |

#### • Environmental

|                     |                                     |
|---------------------|-------------------------------------|
| Operating :         | 0 to 50°C Degree                    |
| Storage :           | -5 to 60°C Degree                   |
| Relative humidity : | 5~90%, non-condensing               |
| Shock :             | 10G acceleration ( 11 ms duration ) |
| Vibration :         | 5~500Hz 1G RMS random vibration     |

#### • Regulatory

|               |                         |
|---------------|-------------------------|
| Safety :      | cUL, FCC & CE certified |
| Environmental | RoHS2 & REACH compliant |

#### • Power

|               |                                       |
|---------------|---------------------------------------|
| Input :       | Auto-sensing 100 to 240VAC, 50 / 60Hz |
| Consumption : | Max. 48 Watt, Standby 5 Watt          |

#### • Product Dimensions ( Single console )

|          |                                               |
|----------|-----------------------------------------------|
| RKP117 : | 441.6 x 460 x 44 mm / 17.4 x 18.1 x 1.73 inch |
| RKP119 : | 441.6 x 500 x 44 mm / 17.4 x 19.7 x 1.73 inch |

#### • Packing Dimensions ( Single console )

|                |                                             |
|----------------|---------------------------------------------|
| RKP117 / 119 : | 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch |
|----------------|---------------------------------------------|

### Console Cable

 

#### CE-6

6 feet Combo KVM cable ( bundle )


- VGA + USB or PS/2, server end
- DB15 ( VGA, USB KB & MS ), console port

### Keyboard

**Ge** G keyboard integrated with touchpad

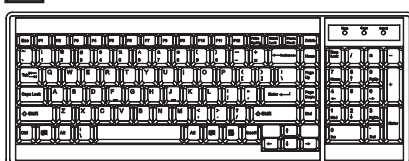

**Gb** G keyboard integrated with trackball

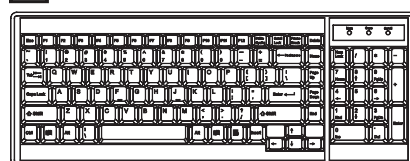

#### Supporting layouts

|         |                                                                                       |                                                                                       |                                                                                       |                                                                                       |                                                                                       |
|---------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
| America |  |                                                                                       |                                                                                       |                                                                                       |                                                                                       |
|         | United States                                                                         |                                                                                       |                                                                                       |                                                                                       |                                                                                       |
| EMEA    |  |  |  |  |  |
|         | United Kingdom                                                                        | Germany                                                                               | France                                                                                | Spain                                                                                 | Norway                                                                                |
|         |  |  |  |  |  |
|         | Italy                                                                                 | Russia                                                                                | Switzerland                                                                           | Netherlands                                                                           | Portugal                                                                              |
| Asia    |  |  |  |  |  |
|         | China                                                                                 | Japan                                                                                 | Korea                                                                                 | Arabia                                                                                | Turkey                                                                                |


**• Product Dimensions ( with KVM )**

RKP117 : 441.6 x 580 x 44 mm / 17.4 x 22.8 x 1.73 inch

RKP119 : 441.6 x 620 x 44 mm / 17.4 x 24.4 x 1.73 inch

**• Packing Dimensions ( with KVM )**

RKP117 : 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

RKP119 : 590 x 808 x 140 mm / 23.2 x 31.8 x 5.5 inch

**• Weight ( Net / Gross )**

RKP117 : 13 kgs ( 28.6 lbs ) 19 kgs ( 41.8 lbs )

RKP119 : 13.7 kgs ( 30.1 lbs ) 19.7 kgs ( 43.3 lbs )

**• Casing Color : Black ( RAL 9005 )**
[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MUKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MUKVM-KIT.pdf)
 stands for 17" or 19" LCD size.

| Matrix<br>Cat6 KVM | Local | Remote | IP | 8-port | 16-port           | 32-port           |
|--------------------|-------|--------|----|--------|-------------------|-------------------|
|                    | 1     | 1      | 1  | -      | RKP11X - MUIP1613 | RKP11X - MUIP3213 |
|                    | 1     | 1      | 2  | -      | RKP11X - MUIP1624 | RKP11X - MUIP3224 |
|                    | 1     | 1      | 0  | -      | RKP11X - MU1602   | RKP11X - MU3202   |
|                    | 1     | 2      | 0  | -      | RKP11X - MU1603   | RKP11X - MU3203   |
|                    | 1     | 3      | 0  | -      | RKP11X - MU1604   | RKP11X - MU3204   |

[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-UKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-UKVM-KIT.pdf)

| Combo<br>Cat6 KVM | Local | Remote | IP | 8-port          | 16-port          | 32-port          |
|-------------------|-------|--------|----|-----------------|------------------|------------------|
|                   | 1     | 0      | 1  | RKP11X - UIP802 | RKP11X - UIP1602 | RKP11X - UIP3202 |
|                   | 1     | 1      | 0  | RKP11X - U802   | RKP11X - U1602   | RKP11X - U3202   |
|                   | 1     | 0      | 0  | RKP11X - U801   | RKP11X - U1601   | RKP11X - U3201   |

Cat6 KVM Dongle : DG-100S ( VGA-USB ) / DG-100 ( VGA-PS/2 ) / DG-100SD ( DVI-USB )

[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf)

| Matrix<br>DB-15 KVM | Local | Remote | IP | 8-port          | 16-port          | 32-port |
|---------------------|-------|--------|----|-----------------|------------------|---------|
|                     | 1     | 1      | 1  | RKP11X - MIP813 | RKP11X - MIP1613 | -       |
|                     | 1     | 1      | 2  | RKP11X - MIP824 | RKP11X - MIP1624 | -       |
|                     | 1     | 1      | 0  | RKP11X - M802   | RKP11X - M1602   | -       |
|                     | 1     | 2      | 0  | RKP11X - M803   | RKP11X - M1603   | -       |
|                     | 1     | 3      | 0  | RKP11X - M804   | RKP11X - M1604   | -       |

[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf)

| Combo<br>DB-15 KVM | Local | Remote | IP | 8-port         | 16-port         | 32-port |
|--------------------|-------|--------|----|----------------|-----------------|---------|
|                    | 1     | 0      | 1  | RKP11X - IP802 | RKP11X - IP1602 | -       |
|                    | 1     | 1      | 0  | RKP11X - 802   | RKP11X - 1602   | -       |
|                    | 1     | 0      | 0  | RKP11X - S801  | RKP11X - S1601  | -       |

Combo DB-15 KVM Cable : CE-6 / 10 / 15 ( 6, 10 or 15 ft )

[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-DVIKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-DVIKVM-KIT.pdf)

| DVI-D<br>KVM | Local | Remote | IP | 12-port        | - | - |
|--------------|-------|--------|----|----------------|---|---|
|              | 1     | 0      | 0  | RKP11X - 1201D | - | - |

DVI-D KVM Cable : CI-6 / 15 ( 6 or 15 ft )

[www.austin-hughes.com/support/usermanual/cyberview/UM-CV-USBKVM-KIT.pdf](http://www.austin-hughes.com/support/usermanual/cyberview/UM-CV-USBKVM-KIT.pdf)

| USB Hub<br>DB-15 KVM | Local | Remote | IP | 8-port          | 16-port          | 32-port |
|----------------------|-------|--------|----|-----------------|------------------|---------|
|                      | 1     | 0      | 1  | RKP11X - IP802H | RKP11X - IP1602H | -       |
|                      | 1     | 1      | 0  | RKP11X - 802H   | RKP11X - 1602H   | -       |
|                      | 1     | 0      | 0  | RKP11X - 801H   | RKP11X - 1601H   | -       |

USB KVM Cable : CB-6 / 10 / 15 ( 6, 10 or 15 ft )