


Product Information Sheet

LOW PROFILE FIXED SHELF

Shelf provides a space-saving and money-saving alternative for storing non-rack mounted equipment without sacrificing CPI Style. This unique telescoping design delivers between 20" and 36" of continuous support for up to 100 pounds of equipment in less than 1 RMU of rack-mount space!

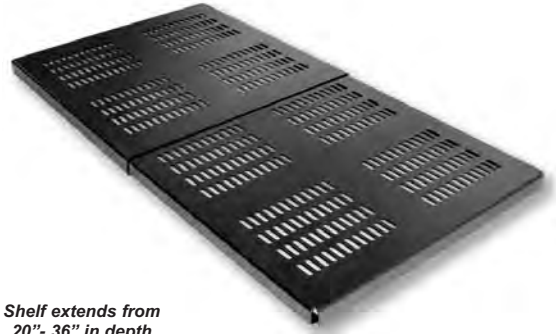

Shelf extends from 20"- 36" in depth

- Shelf bracket provides front and rear support, attaching with single screw to mounting rails
- Available in 19" & 23" EIA widths, providing 17.5" & 21.5" surface space respectively
- Made of 16-gauge cold rolled steel, finished with semi gloss polyester-hybrid powder coat paint
- Available in solid and vented
- 19"W versions are UL Listed 60950 (File E227626)

Part Number	Description	Shipping Weight
12573-X19	19"W Solid Shelf	16 lb (7.3 kg)
12573-X23	23"W Solid Shelf	18 lb (8.2 kg)
12610-X19	19"W Vented Shelf	15 lb (6.8 kg)
12610-X23	23"W Vented Shelf	17 lb (7.7 kg)

X=color: 1=Gray, 2=White, 7=Black

800-834-4969 in U.S. & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS, INC.

All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only. While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products

©2007 Chatsworth Products, Inc. All rights reserved. CPI, Saf-T-Grip, Seismic Frame, SlimFrame and MegaFrame are federally registered trademarks of Chatsworth Products, Inc. CPI Passive Cooling, Cube-iT Plus, EasySwing, FastTrac, Multi-Mount, Structured Termination Systems, TeraFrame, Thinline, QuadraRack and Universal Rack are trademarks of Chatsworth Products, Inc. All other trademarks belong to their respective companies.