


# Product Cut Sheet

## POWER STRIP FOR CUBE-IT PLUS® CABINET SYSTEM

Mounts inside the top, bottom or side of Cube-iT Plus Cabinet

- Six or Eight 3-prong, 15A or 20A, 110-125 Vac outlets
- Circuit breaker provides basic over-current protection
- Optional surge protection provides basic voltage-spike protection (1100 Joules, LED indicator)
- IEC C20 power inlet with cord retention bracket
- Includes detachable power cord with NEMA plug
- Select straight or locking plug
- Includes mounting bracket and installation hardware
- UL Listed

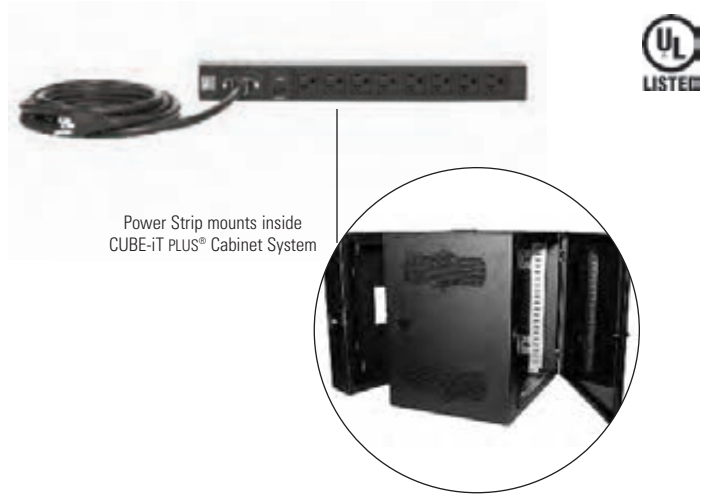

Part Number	Input			Output		Dims - in (mm)		
	Amp	kW	Plug	Breakers	Outlets	H	W	D
<b>110-125 Volt, Single-Phase Power Strip</b>								
12820-701	15	1.4	NEMA 5-15P	1 x 15A	(8) 5-15R	19.2 (488)	1.8 (44)	2.7 (68)
12820-702	15	1.4	NEMA L5-15P	1 x 15A	(8) 5-15R	19.2 (488)	1.8 (44)	2.7 (68)
12820-705	20	1.9	NEMA 5-20P	1 x 20A	(8) 5-20R	19.2 (488)	1.8 (44)	2.7 (68)
12820-706	20	1.9	NEMA L5-20P	1 x 20A	(8) 5-20R	19.2 (488)	1.8 (44)	2.7 (68)
<b>110-125 Volt, Single-Phase Power Strip, Surge-Protected</b>								
12820-703	15	1.4	NEMA 5-15P	1 x 15A	(6) 5-15R	19.2 (488)	1.8 (44)	2.7 (68)
12820-704	15	1.4	NEMA L5-15P	1 x 15A	(6) 5-15R	19.2 (488)	1.8 (44)	2.7 (68)
12820-707	20	1.9	NEMA 5-20P	1 x 20A	(6) 5-20R	19.2 (488)	1.8 (44)	2.7 (68)
12820-708	20	1.9	NEMA L5-20P	1 x 20A	(6) 5-20R	19.2 (488)	1.8 (44)	2.7 (68)

*Notes: Dimensions include mounting bracket in vertical orientation. The Power Strip is 17"H (432 mm) by 1.7"W (43 mm) by 1.4"D (36 mm). All power strips have IEC C20 inlets and include a power cord. Cords with locking plugs are 10'L (3 m). Cords with straight plugs are 8'2"L (2.4 m).*

800-834-4969 in U.S. & Canada • [www.chatsworth.com](http://www.chatsworth.com)