

AIPHONE®

JP Series


Video Intercom with Enhanced Picture Quality



EASILY IDENTIFY VISITORS

JP Series Video Intercom with Enhanced Picture Quality

JP Series Video Door Stations or GT-D Audio Door Station

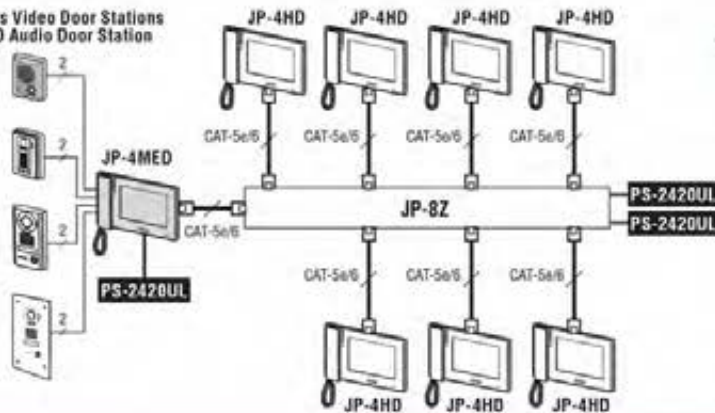

JP Series Features

- Digital PanTilt and Zoom camera eliminates blind spots with 170° wide angle lens (video door stations)
- Card and keypad access door stations available
- Hands-free (VOX) or handset communication
- Includes two N/O door release contacts
- Picture memory records up to 20 calls to internal memory and max. 1,000 calls to removable SD/SDHC card (not included)
- Entry can be monitored via the master station
- 1 output to control a secondary device like a light, gate, or additional door
- Video out to DVR via supplied connector
- Homerun or daisy chain wiring options

Start Here! Select one box set



JP-4AED
JP-4MED, JP-DA, PS-2420UL



JP-4AEV
JP-4MED, JP-DV, PS-2420UL



JP-4AEF
JP-4MED, JP-DVF, PS-2420UL

Add more inside stations (Up to 7 JP-4HD stations)



JP-4HD
Video Sub Master Station
(Up to 7 per JP-4MED)

- 7" Touchscreen LCD
- Hands-free communication with handset for privacy
- Homerun with Cat-5e/6



JP-8Z
Distribution Adaptor for Sub Master Stations

Add more door stations (Up to 4 TOTAL per system)



JP-DA
Video Door Station

- PTZ camera
- Plastic cover
- Surface mount



JP-DV
Video Door Station

- PTZ camera
- Zinc die cast
- Surface mount



JP-DVF
Video Door Station

- PTZ camera
- Stainless steel
- Flush mount
- Mounting box included



GT-D
Audio Door Station

- Plastic cover
- Surface mount

JP Series Specifications

Power Source - 24V DC - use PS-2420UL

Communication - Hands-free (VOX) or handset (full-duplex)

Video Display - 7" color LCD touchscreen

Picture Memory - Internal / Built-In: record max. 20 calls (6 images per call) with up to 5 calls protected from overwriting
SD/SDHC card: record max. 1,000 calls (40 images per call) with up to 100 calls protected from overwriting

Camera - Type: 1/4" color CMOS
View Area: 100° vert. x 170° horiz.

Door Release - N/O dry contact, 24V AC/DC, 500mA - use EL-12S (use RY-24L for larger contact rating and use RY-3DL for 3-4 doors)

Wire Type

Door Station to Master Station: 2-cond., mid cap, solid, non-shielded - use Aiphone #871802

Power Supply to Master Station: 2-cond., mid cap, solid, non-shielded - use Aiphone #871802

Master Station to Adaptor: CAT-5e or CAT-6

Adaptor to Sub Master Station: CAT-5e or CAT-6

Distance

Door Station to Master Station: 330'

Master Station to Distribution Adaptor: 650'

Distribution Adaptor to Sub Master Station: 165'

Power Supply to Master Station: 16'(22AWG) 33'(18AWG)

Power Supply to Distribution Adaptor: 16'(22AWG) 33'(18AWG)

JP Series
Sales Sheet

To schedule a live product demonstration, visit www.aiphone.com/demo

