

## LWM41 Mount

### WALL MOUNT, LEGACY® SERIES, PAN/TILT

#### Product Features


- Easy to Install
- Lightweight, Cast-Aluminum Construction
- Supports up to 150 Pounds (68 kg)
- For Use with Legacy® Integrated Positioning Systems
- Can Be Used with Optional Legacy LRD41 Series Receiver
- Optional Access Panel Lock Kit
- Optional Corner, Parapet, and Pole Adapters Available

The **LWM41** is a wall mount designed for use with all Legacy® integrated positioning systems.

Constructed from cast aluminum, the **LWM41** is capable of supporting up to 150 pounds (68 kg). This timesaving and easy-to-install mount houses the entire Legacy system (pan/tilt, enclosure, and receiver) in one location. Video and power cables can be routed through the rear or bottom of the mount. A optional block-off plate is supplied for NEMA Type 4 and conduit applications. The bottom access panel is easily accessible for installation and maintenance of the optional receiver, and an access panel lock kit (LK4500) is available for additional security.

Optional Coaxitron® receiver (LRD41A11 or LRD41C21/LRD41C22 Series) is available in fixed or variable speed models, with or without presets. Also available is an optional LRD41TLC test/local control module for testing system and lens functions. This plug-in module operates on +5 VDC supplied by the receiver.

The **LWM41** can be adapted for use in corner, pole, and parapet applications when used with the appropriate mount adapter.

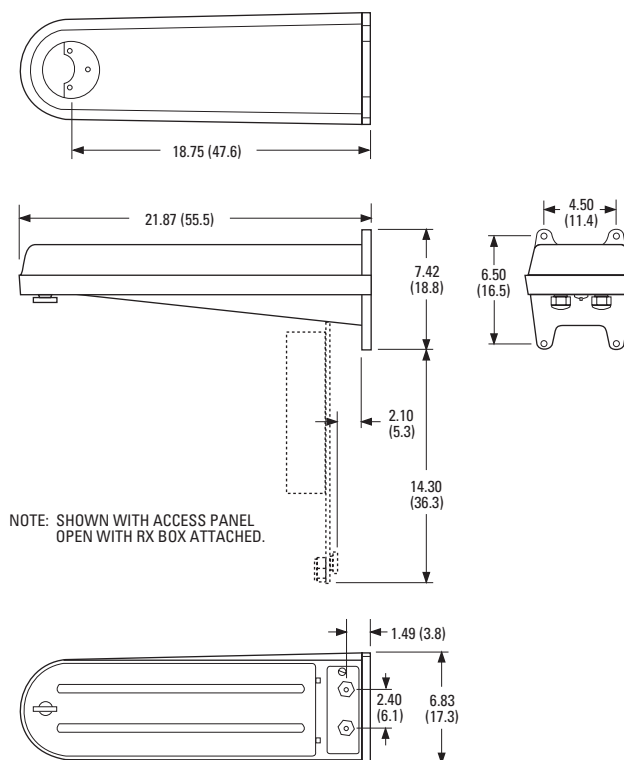

NOTE: VALUES IN PARENTHESES ARE CENTIMETERS; ALL OTHERS ARE INCHES.



# TECHNICAL SPECIFICATIONS

## MODEL

LWM41	Wall mount for Legacy® integrated positioning system and optional receiver
-------	--

## RELATED PRODUCTS

Legacy® Integrated Positioning Systems	Medium-duty system (EH4700L and EH5700L Series enclosure and PT780 Series pan/tilt). Medium-duty system (EH8106L pressurized enclosure and PT780 Series pan/tilt).
LRD41A11 Series	Legacy fixed speed receiver, Coaxitron® compatible.
LRD41C21 Series	Legacy fixed speed receiver, Coaxitron/RS-422 compatible with up to 64 presets.
LRD41C22 Series	Legacy variable speed receiver, Coaxitron/RS-422 compatible with up to 64 presets.
LRD41TLC	Test/local control module for use with optional receiver.

## MECHANICAL

Pan/Tilt Mounting	Four 1/4-20 x 5/8-inch cap screws and washers (supplied) for attaching pan/tilt
Mounting Method	Secure with four fasteners suitable for mounting surface (minimum 5/16-inch recommended, not supplied)

## GENERAL

Construction	Aluminum casting
Finish	Gray polyester powder coat
Maximum Load	150 lb (68 kg)
Unit Weight	9.51 lb (4.32 kg)
	14 lb (6.35 kg) approximate with receiver installed
Shipping Weight	12 lb (5.44 kg)

## CERTIFICATIONS/RATINGS

- Meets NEMA Type 4 standards (with all factory-supplied gaskets and block-off plates installed)

## OPTIONAL ACCESSORIES

LK4500	Lock kit (with keys) for LWM41 wall mount access panel
--------	--

## OPTIONAL MOUNT ADAPTERS

CM400	Corner mount adapter.
PA402	Pole mount adapter. Minimum pole diameter 3 inches.
PP300L	Parapet corner mount adapter. Mounts on top of rooftop or parapet.
PP301L	Parapet corner mount adapter. Mounts to inside of parapet.
PP400	Parapet mount adapter. Mounts to inside/outside of parapet wall.
PP4348	Parapet mount. Mounts to rooftop or horizontal flat surface.



**Pelco, Inc. Worldwide Headquarters:**  
3500 Pelco Way, Clovis, California 93612-5699 USA  
**USA & Canada** Tel: (800) 289-9100 • FAX: (800) 289-9150  
**International** Tel: +1 (559) 292-1981 • FAX: +1 (559) 348-1120  
[www.pelco.com](http://www.pelco.com)

Pelco, the Pelco logo, Coaxitron, and Legacy are registered trademarks of Pelco, Inc.  
Specifications subject to change without notice.  
©Copyright 2000, Pelco, Inc. All rights reserved.