


Fan Module for inorax-AI Series

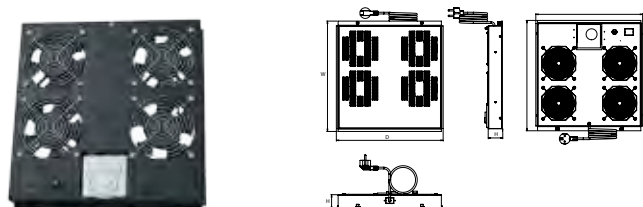

Operating Voltage AC 220 - 240 Volts 50/60 Hz

Standards Conforms to IEC 297-1 **Air Flow** 95 -115 CFM

Noise 44 - 49 dB (A) **Material** 1,5 mm Steel

Fan Speed 2700 - 3100 rpm **Finish** Electrostatic Powder Paint

Packaging One piece in a box

H (mm)	D (mm)	W (mm)	Number of Fans	Weight kg	Part No
47	375	363	2	3,76	CPA-X-2001
47	375	363	4	4,81	CPA-X-2002
47	510	363	6	6,74	CPA-X-2003



www.facebook.com/canovategroup



www.linkedin.com/company/canovate-group



[canovatesales](https://twitter.com/canovatesales)

© Copyright 2013 Canovate Group. The information contained herein is subject to change without notice. The only warranties for Canovate products and services are set forth in the express warranty statements accompanying such products and services. Nothing herein should be construed as constituting an additional warranty. Canovate shall not be liable for technical or editorial errors or omissions contained herein.

www.canovate.com | info@canovate.com | P. +90 216 484 2222

Document Name: Accessories

Publication Date : 23/10/14