

PCD Series

plastic cable ducts

cost effective solution for open racks

features:

- Available in 1½", 2", 3", and 4" widths
- Available in 3" and 4" depths, single channel and 6" and 8" depths dual channel
- Slotted finger design allows for horizontal cable access exactly where it's needed
- Includes mounting hardware
- Also available as raw duct without mounting ears (1.5" width)
- Fingers can be easily removed to create larger openings
- Hinged plastic covers provide organization while keeping cables hidden
- Ideal for medium to low density installations
- Can be mounted in-between racks for 38 space and higher



PCD shown on RLA series
2 post rack

specifications:

PCD Series Plastic Cable Duct shall be Middle Atlantic Products model # PCD-___ (refer to chart). PCD shall be constructed of interior grade rigid PVC and include a hinged plastic cover. PCD shall dimensions shall be _"H x _"D x _"W (refer to chart). PCD shall comply with requirements of RoHS EU Directive 2002/95/EC. PCD shall be manufactured by an ISO 9001 and ISO 14001 registered company. PCD shall be warrantied to be free from defects in material and workmanship under normal use and conditions for the lifetime of the product.

Customizable specification clips available at middleatlantic.com



what **great systems** are built on.™

A Group brand | **legrand**

Middle Atlantic Products

middleatlantic.com | middleatlantic.ca


96-01115 / rev b / 11-5-14

PCD Series



basic dimensions

all dimensions in inches unless otherwise noted [all dimensions in brackets are in millimeters]

PCD single

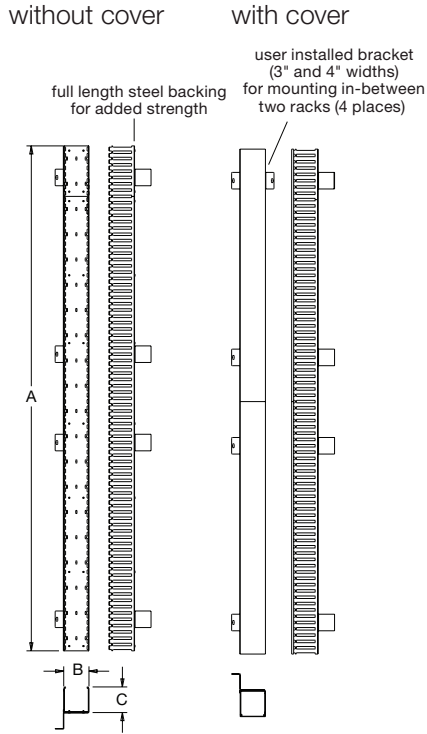

PCD dual

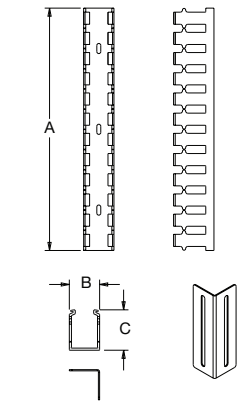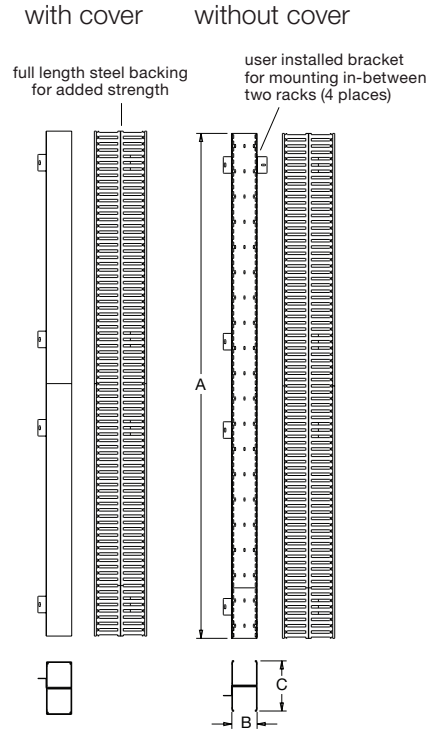

PCDB-90-1.5-12
optional mounting bracket
to orient duct 90 for use with
PCD-1.5-2-4BK & PCD-1.5-4BK
only includes 12 brackets

PCD Series Single	"A" Length (in)	"B" Width (in)	"C" Depth (in)
PCD-2-3-8SC	16 [406.4]	2 [50.8]	3.06 [77.72]
PCD-2-3-12SC	23.875 [606.43]	2 [50.8]	3.06 [77.72]
PCD-2-3-15SC	28 [711.2]	2 [50.8]	3.06 [77.72]
PCD-2-3-20SC	35.875 [911.23]	2 [50.8]	3.06 [77.72]
PCD-2-3-25SC	44 [1117.6]	2 [50.8]	3.06 [77.72]
PCD-2-3-30SC	56 [1422.4]	2 [50.8]	3.06 [77.72]
PCD-2-3-38SC	68 [1727.2]	2 [50.8]	3.06 [77.72]
PCD-2-3-45SC	80 [2023]	2 [50.8]	3.06 [77.72]
PCD-3-3-38SC	68 [1727.2]	3 [76.2]	3.06 [77.72]
PCD-3-3-45SC	80 [2032]	3 [76.2]	3.06 [77.72]
PCD-4-4-38SC	68 [1727.2]	4 [101.6]	4.06 [103.12]
PCD-4-4-45SC	80 [2023]	4 [101.6]	4.06 [103.12]
PCD-4-4-51SC	92 [2336.8]	4 [101.6]	4.06 [103.12]
PCD-1.5X2-4BK*	72 [1828.8]	1.5 [38.1]	2 [50.8]
PCD-1.5X4-4BK*	72 [1828.8]	1.5 [38.1]	4 [101.6]

PCD Series Dual	"A" Length (in)	"B" Width (in)	"C" Depth (in)
PCD-3-6-38DC	68 [1727.2]	3 [76.2]	6.06 [153.92]
PCD-3-6-45DC	80 [2023]	3 [76.2]	6.06 [153.92]
PCD-4-8-38DC	68 [1727.2]	4 [101.6]	8.06 [204.72]
PCD-4-8-45DC	80 [2032]	4 [101.6]	8.06 [204.72]
PCD-4-8-51DC	92 [2336.8]	4 [101.6]	8.06 [204.72]

* does not include brackets, includes mounting hardware

** does not include brackets, does not include mounting hardware, includes 4 pieces

what great systems are built on.™

A Group brand | **legrand**

Middle Atlantic Products
middleatlantic.com | middleatlantic.ca