


**Middle Atlantic Products**

EXCEPTIONAL SUPPORT &amp; PROTECTION™

# PD Series Slim Power Strips



**High density power strips feature a slim, low-profile design and staggered outlets to accommodate plug-in power supplies**

## Features

- UL Listed and CSA certified (PD-2420SC-NS UL Listed only)
- (1) 15 or 20 amp circuit depending on model
- Includes SignalSAFE™ power cord terminated with NEMA 5-15P or NEMA 5-20P plug depending on model
- Up to 24 outlets depending on model
- Outlets spaced to accommodate plug-in power supplies
- Circuit breaker or MOV surge & EMI filter & breaker protected, depending on model
- Mounting hardware included
- Slim low-profile design requires less space
- Gray outlets easy to see in rear of enclosures
- Lightweight anodized aluminum chassis

\* For additional Vertical Power Strips, please see A&E Spec # 96-938



## Architects' and Engineers' Specifications

High density slim power strip shall be Middle Atlantic Products model # PD-\_\_\_ with \_\_\_ outlets and \_\_\_ amps (refer to chart). Slim power strip shall be \_\_\_" long x 1.25" deep x 1.6" wide and shall have gray \_\_\_ NEMA \_\_\_ outlets (refer to chart) in unique spacing pattern that allows up to \_\_\_ plug-in power supplies (refer to chart). Slim power strip includes \_\_\_ amp circuit breaker protection and mounting hardware (refer to chart). Terminated with \_\_\_ (refer to chart) SignalSAFE™ power cord with NEMA \_\_\_ plug (refer to chart). Grounding and bonding stud shall be 1/4 - 20 threaded. Slim power strip shall be ETL listed to UL standards 1149 and 1363 in US and to CAN/CSA standard C22.2 #8 and C22.2 #21 in Canada. Slim power strip shall be RoHS EU Directive 2002/95/EC compliant. Slim power strip shall be GREENGUARD Indoor Air Quality Certified for Children and Schools. Slim power strip shall be manufactured by an ISO 9001 registered company. Slim power strip shall be warranted to be free from defects in material or workmanship under normal use and conditions for a period of 3 years.


### OPTIONS

- Model # PB-XS, rackmounting bracket shall mount any 8 outlet power strip (PD-815SC, PD-815SC-NS) between rackrail of any EIA compliant 19" rack. Includes cable management tie points
- Model # PB-5A mounting brackets shall accommodate the mounting of vertical power strips to rackrail of any rack
- Model # PB-DWR mounting bracket shall accommodate the mounting of vertical power strips to rear rackrail of Middle Atlantic Products DWR & SR series wall racks



**CUSTOMIZABLE SPECIFICATION CLIPS AVAILABLE AT MIDDLEATLANTIC.COM**

# PD Series Slim power strips basic dimensions



All dimensions in inches unless otherwise noted [All dimensions in brackets are millimeters]

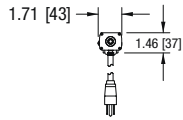


PD-24XXSC-XX

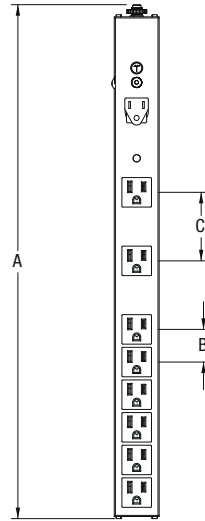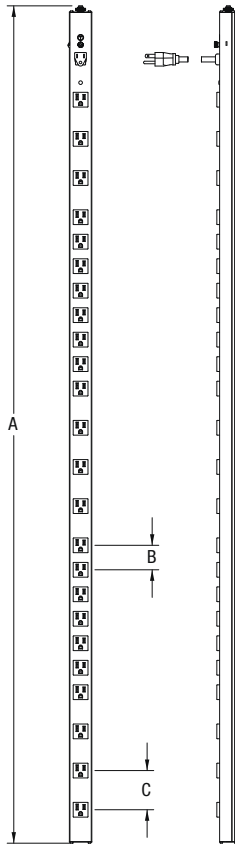

PD-815SC-XX

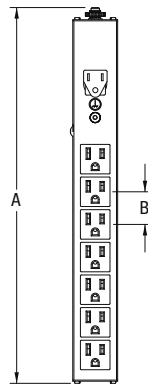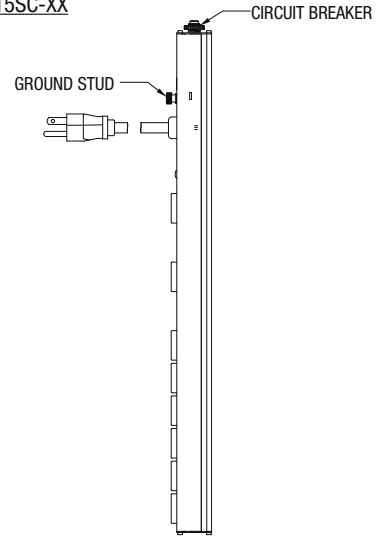

PD-715SC-NS

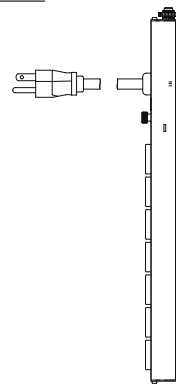

NOTE:  
1) PD SLIM SERIES INCLUDES SIGNALSAFE™ POWER CORD TECHNOLOGY

PART #	A OVERALL LENGTH	B OUTLET SPACING	C OUTLET SPACING	# OF PLUG IN POWER SUPPLIES ACCOMMODATED	# OF OUTLETS	OUTLET TYPE	CORD LENGTH/ TERMINATION	CIRCUIT	SURGE PROTECTION	OVERCURRENT PROTECTION
PD-715SC-NS	13.60 [345]	1.18 [30]	N/A	1	7	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	none	circuit breaker
PD-815SC	18.60 [472]	1.18 [30]	2.48 [63]	3	8	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	single stage	circuit breaker
PD-815SC-20	18.60 [472]	1.18 [30]	2.48 [63]	3	8	5-15R	20' cord w/NEMA 5-15 plug	15 AMP (1)	single stage	circuit breaker
PD-815SC-NS	18.60 [472]	1.18 [30]	2.48 [63]	3	8	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	none	circuit breaker
PD-815SC-PBSH*	18.60 [472]	1.18 [30]	2.48 [63]	3	8	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	single stage	circuit breaker
PD-2415SC	60.60 [1539]	1.77 [45]	2.84 [72]	11	24	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	single stage	circuit breaker
PD-2415SC-NS	60.60 [1539]	1.77 [45]	2.84 [72]	11	24	5-15R	10' cord w/NEMA 5-15 plug	15 AMP (1)	none	circuit breaker
PD-2420SC-NS	60.60 [1539]	1.77 [45]	2.84 [72]	11	24	5-15R (22), 5-20R (2)	10' cord w/NEMA 5-20 plug	20 AMP (1)	none	circuit breaker

\*PD-815SC-PBSH mounts on UXV Series fully vented utility shelves, RC and CAP Series clamping rackshelves, VRS - Vertical Rackmount Shelves, KD Series ready-to-assemble rackshelves, RSH Series custom face rackmounts