

# 5G110-BP5



**UPC Code:** 07847720824

**Country of Origin:** United States - *\*Eligible for ARRA funded projects*



*\*May include one or more globally sourced components.*



## Connectors

### Item Description

GigaMax 5e+ QuickPort Connector Quickpack, 25-pack, Purple

### Technical Information

#### Environmental Specifications

**Flammability:** Rated UL94V-0

#### Material Specifications

**Contact Surface Material:** 50 microinches thick Gold-Plated

**Contact Sub-Surface Material:** 100 microinches thick Nickel-Plated

**Contact Base Material:** Phosphor Bronze

**Body Material:** High-Impact Fire-Retardant Plastic

**Body Color:** Purple

#### Mechanical Specifications

**Position / Conductor:** 8P8C

**Style Name:** GigaMax

**Termination Type:** 110 Punchdown

**Connector Feature:** Channel/Component Rated

**Cable Type:** 8-Conductor UTP Copper Cat 5, 5e and 6

**Product ID:** Permanently laser-engraved

**Wiring Standard:** T568A T568B

#### Performance Specifications

**Module Type:** Category 5e Plus

#### Product Features

**Module Style:** Connector

**Module Type:** Category 5e Plus

**Position / Conductor:** 8P8C

**Cable Type:** 8-Conductor UTP Copper Cat 5, 5e and 6

**Connector Feature:** Channel/Component Rated

**Termination Type:** 110 Punchdown

**Contact Surface Material:** 50 microinches thick Gold-Plated

**Contact Sub-Surface Material:** 100 microinches thick Nickel-Plated

**Contact Base Material:** Phosphor Bronze

**Category Rating:** GigaMax 5e+

**Body Color:** Purple

**Standards and Certifications:** TIA/EIA cULus Listed

**Warranty:** 1 Year Limited

**Packaging:** QuickPack 25/bag

**Color:** Purple

**Ordering Notes:** Bulk Package of 25

#### Standards and Certifications

**TIA/EIA:** TIA-568-B

**UL:** cULus Listed


**ISO/IEC:** 11801

**CSA:** Certified

**NEC:** Article 800 Compliant

**FCC:** Part 68 Compliant

**ACA:** Compliant

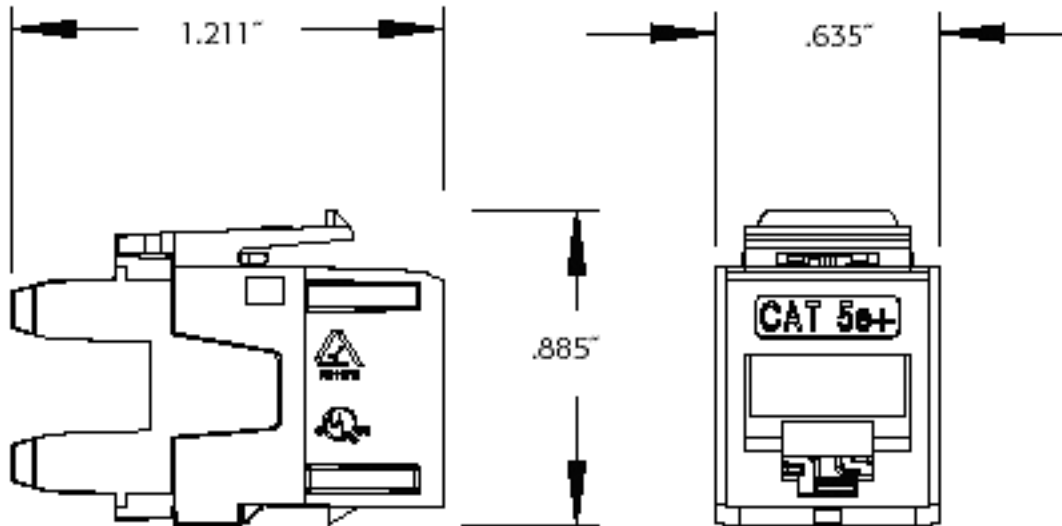

Side View

Front View

**SPECIFICATION SUBMITTAL**

JOB NAME:		CATALOG NUMBERS:	
<input type="text"/>		<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>	<input type="text"/>

**Leviton Manufacturing Co., Inc.**  
 201 North Service Road, Melville, NY 11747  
 Telephone: 1-800-323-8920 · FAX: 1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**  
 165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: 1-800-469-7890 ·  
 FAX: 1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**  
 Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)  
 © 2012-2015 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.



**Leviton has a global presence.**  
 If you would like to know where your local Leviton office is located please go to: [www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

*\*Buy American Compliant Logo -- The American Recovery And Reinvestment Act of 2009 ("ARRA") provides federal grants and loans for projects throughout the country. Section 1605 of the Act, named the "Buy American" provision, requires that certain materials and manufactured products used in projects funded by the Act be manufactured in the United States. The appearance of the Recovery Act Logo in relation to a Leviton product is only intended to reflect that such product may be used in an ARRA funded project. It does not mean that such product or Leviton is sponsored or endorsed by, or that Leviton receives funds from, the federal government or the Recovery Accountability and Transparency Board. Nothing in Leviton's use of the logo is intended to suggest anything regarding the requirements for funding under ARRA.*