


## ETS1A-PNMDM

**ETS1-50T SureFlex™ Jumper with interface types N Male and 7-16 DIN Male, variable length**

### General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	ETS1-50T
Interface, Connector A	N Male
Interface, Connector B	7-16 DIN Male
Variable Length	For custom lengths contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or an Andrew representative

### Jumper Assembly Sample Label

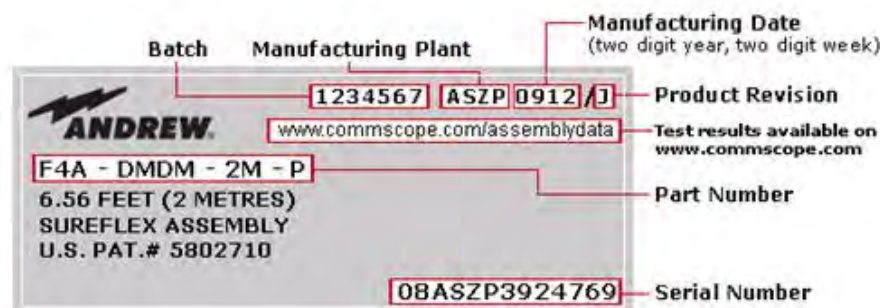

### Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
700-3000 MHz	1.29	18.00

### Regulatory Compliance/Certifications


Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



### Included Products

ETS1-HRL — ETS1-50T, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4 in, brown TPC-ET jacket

 ETS1A-PNMDM



**PTS1-HRL** — PTS1-50, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4 in, brown TPC-ET jacket