




ETS1B-PTMDF-1M

ETS1-50T SureFlex™ Jumper with interface types TNC Male and 7-16 DIN Female, 1 m

General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	ETS1-50T
Interface, Connector A	TNC Male
Interface, Connector B	7-16 DIN Female
Length	1.000 m 3.281 ft
Attachment, Connector A	Field attachment

Jumper Assembly Sample Label

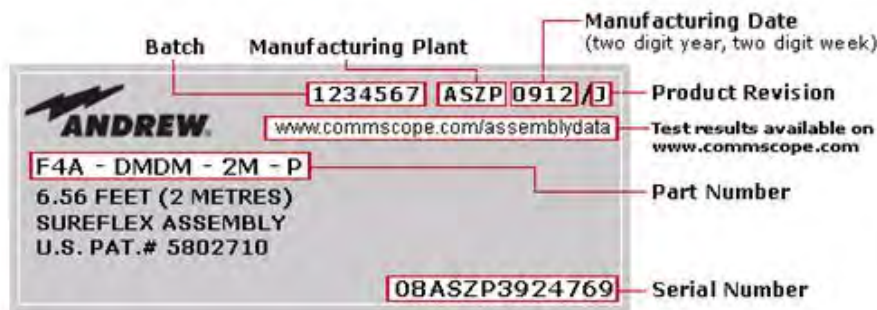

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
700-3000 MHz	1.22	20.00

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system




Included Products

F1TTM-C — TNC Male for 1/4 in FSJ1-50A cable

ETS1-HRL — ETS1-50T, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4

 Product Specifications



ETS1B-PTMDF-1M

in, brown TPC-ET jacket

PTS1-HRL — PTS1-50, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4 in, brown TPC-ET jacket