




ETS1-PSMSM

ETS1-50T Jumper with interface types SMA Male and SMA Male, variable length

General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Straight
Cable Family	ETS1-50T
Interface, Connector A	SMA Male
Interface, Connector B	SMA Male
Variable Length	For custom lengths contact 1-800-255-1479 (North America), 1-779-435-6500 (International), or an Andrew representative

Jumper Assembly Sample Label

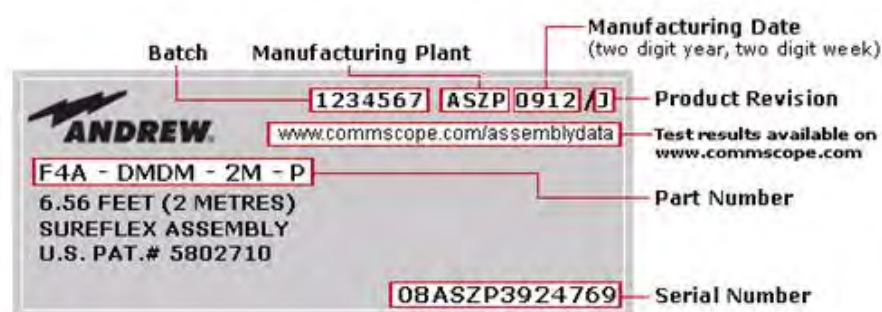

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
700-3000 MHz	1.22	20.00

Regulatory Compliance/Certifications


Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



Included Products

- F1TSM-HF — SMA Male for 1/4 in FSJ1-50A cable
- F1TSR-HF — SMA Male Right Angle for 1/4 in FSJ1-50A cable

 ETS1-PSMSM



ETS1-HRL — ETS1-50T, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4 in, brown TPC-ET jacket

PTS1-HRL — PTS1-50, HELIAX® Superflexible High Power, High Temperature Foam Coaxial Cable, corrugated copper, 1/4 in, brown TPC-ET jacket