




F2A-PNMNR-8
FSJ2-50 SureFlex® Jumper with interface types N Male and N Male Right Angle, 2.44 m

General Specifications

| | |
|------------------------------------|--------------------|
| Body Style, Connector A | Straight |
| Body Style, Connector B | Right angle |
| Cable Family | FSJ2-50 |
| Interface, Connector A | N Male |
| Interface, Connector B | N Male |
| Nominal Size | 3/8 in |
| Length | 2.440 m 8.005 ft |
| Specification Sheet Revision Level | A |

Jumper Assembly Sample Label

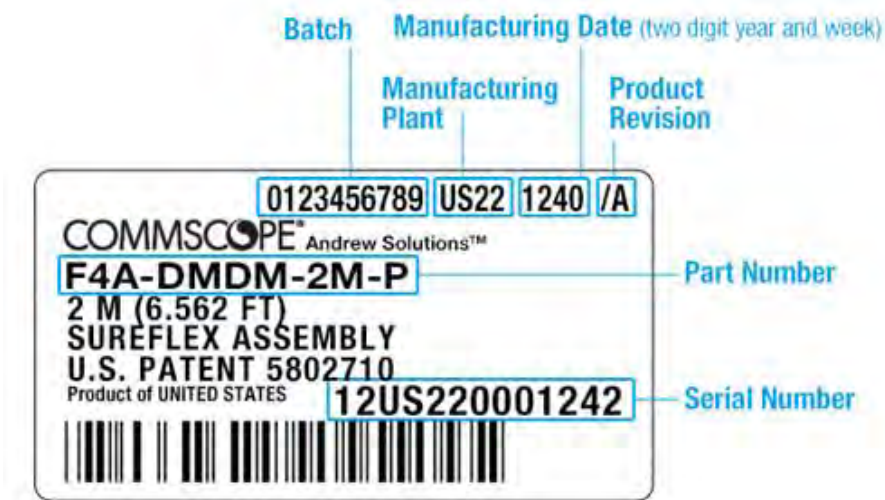

Return Loss/VSWR

| Frequency Band | VSWR | Return Loss (dB) |
|----------------|------|------------------|
| 700–3000 MHz | 1.29 | 18.00 |

Regulatory Compliance/Certifications

| Agency | Classification |
|----------------------------|--|
| RoHS 2011/65/EU | Compliant by Exemption |
| China RoHS SJ/T 11364-2006 | Above Maximum Concentration Value (MCV) |
| ISO 9001:2008 | Designed, manufactured and/or distributed under this quality management system |



F2A-PNMMNR-8

POWERED BY



Included Products

FSJ2-50 — FSJ2-50, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 3/8 in, black PE jacket