



F4A-DM-30-P

FSJ4-50B SureFlex™ Jumper with interface type 7-16 DIN Male, 30 ft.


General Specifications

Body Style, Connector A	Straight
Cable Family	FSJ4-50B
Interface, Connector A	7-16 DIN Male
Interface, Connector B	Sold separately
Length	9.144 m 30.000 ft

Electrical Specifications

3rd Order IMD	-116.00 dBm
DTF, Connector A	-34.00 dB

Jumper Assembly Sample Label

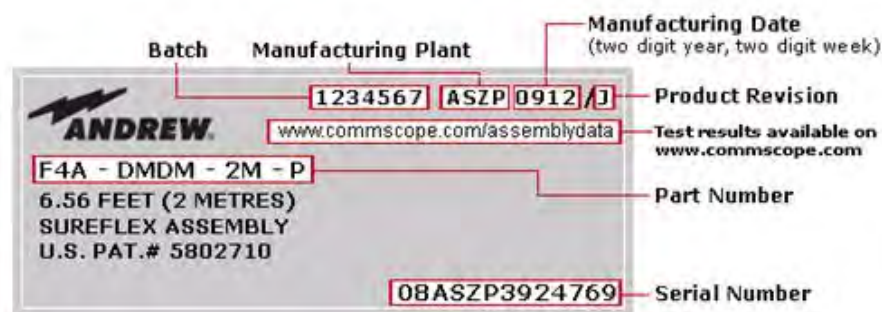

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698-960 MHz	1.10	26.40
1700-2200 MHz	1.10	26.40

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system



Included Products

FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket