



## F4A-DMDR-7M-PV

**FSJ4-50B-100 SureFlex™ Jumper with interface types 7-16 DIN Male and 7-16 DIN Male Right Angle, 7 m**


### General Specifications

Body Style, Connector A	Straight
Body Style, Connector B	Right angle
Cable Family	FSJ4-50B
Interface, Connector A	7-16 DIN Male
Interface, Connector B	7-16 DIN Male
Length	7.000 m   22.966 ft

### Electrical Specifications

3rd Order IMD	-116.00 dBm
DTF, Connector A	-34.00 dB
DTF, Connector B	-32.00 dB

### Jumper Assembly Sample Label

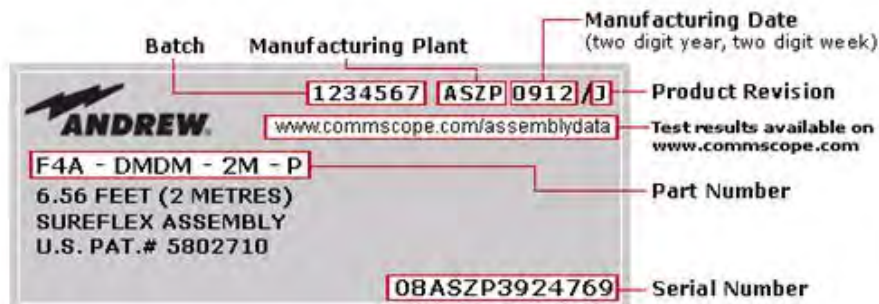

### Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698–960 MHz	1.1	26.40
1700–2200 MHz	1.1	26.40

### Regulatory Compliance/Certifications

 
Agency	Classification
RoHS 2002/95/EC	Compliant by Exemption
China RoHS SJ/T 11364-2006	Above Maximum Concentration Value (MCV)



# Product Specifications

COMMScope®

F4A-DMDR-7M-PV



## Included Products

---

FSJ4-50B — FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket